

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0982660436](#)
Status: **Active**
Overview: Premo-Flex Cable Jumpers
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 40 Circuits, 0.152m Cable Length, Tin(Sn) Plating

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-98266-001-001 \(PDF\)](#) [Product Literature \(PDF\)](#)

General

| | |
|-----------------------------|--|
| Product Family | Cable |
| Series | 98266 |
| Comments | Contacts on opposite sides, Type D |
| Crimp Quality Equipment | Yes |
| Overview | Premo-Flex Cable Jumpers |
| Product Literature Order No | 987650-6631 |
| Product Name | Premo-Flex FFC Jumper |
| UPC | 756054768907 |

Physical

| | |
|-------------------------------|-----------------|
| Cable Length | 0.152m |
| Circuits (Loaded) | 40 |
| Net Weight | 1.972/g |
| Packaging Type | Bag |
| Pitch - Termination Interface | 0.50mm |
| Temperature Range - Operating | -40° to +105°C |
| Wire Size AWG | N/A |
| Wire/Cable Type | Flat Flex Cable |

Electrical

| | |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.5A |
| Voltage - Maximum | 60V AC |


Solder Process Data

| | |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

Material Info

Reference - Drawing Numbers

| | |
|-------------------------|------------------|
| Packaging Specification | PK-98266-001-001 |
| Sales Drawing | SD-98266-001 |

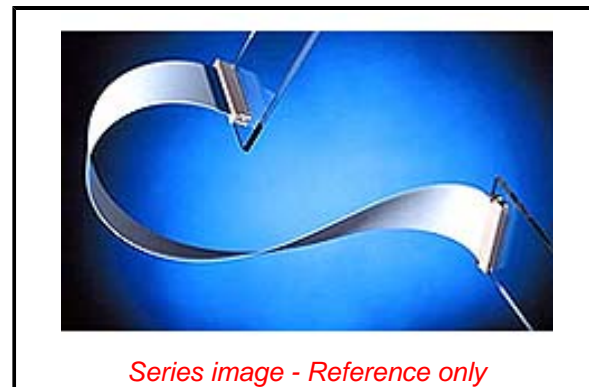

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[98266 Series](#)

Use With

Molex FFC – FPC connector. Be sure to match like plating.