


EREM

Part Number: 896E

Description: Side cutter - oval head, suitable for cutting hard wires, Kovar®, connector pin

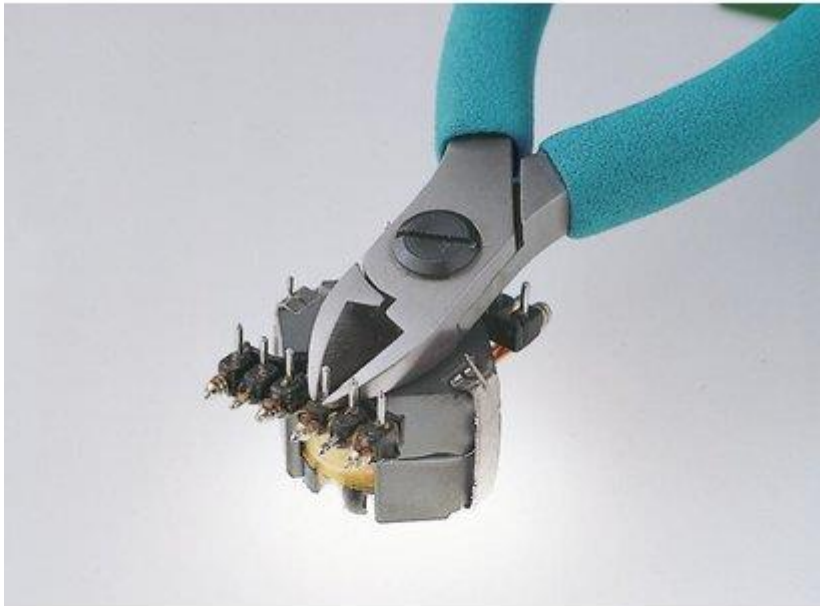

Fits for all cutting applications where easy access is given  
It is robust and size for size offers the highest cutting capacity.  
This is the most widely used head shape.

Technical Data:

Length mm	120
Length of cutting edges mm	15
Head width mm	13.5
Head thickness mm	7.2
Head length mm	21
Max. cutting capability – hard wire mm	Ø 0,6
Max. cutting capability – medium hardness mm	Ø 1,2
Max. cutting capability – copper wire mm	Ø 1,8
Weight in g	67
Length of cutting edges inches	0.590

Head width inches	0.531
Head thickness inches	0.284
Head length inches	0.827
ESD-safe	on
Length inches	4.724