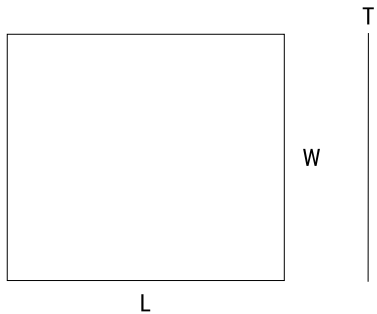


KEMET, EFG2, Flex Suppressors, Noise Suppression

**Dimensions**

Sheet Size	80x80mm
L	80mm NOM
W	80mm NOM
T	0.3mm NOM

Packaging Specifications

Weight:	7.58 g
---------	--------

General Information

Series:	EFG2
Style:	Sheet
Description:	Flex Suppressor GHz Band High Performance Type
Features:	GHz Band High Performance Type, Wi-Fi, GPS, LTE-A
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Specifications

Temperature Range:	-40/+105C
Magnetic Permeability:	35 u At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.9 Atm TYP