


KEMET, EFA, Flex Suppressors, Noise Suppression

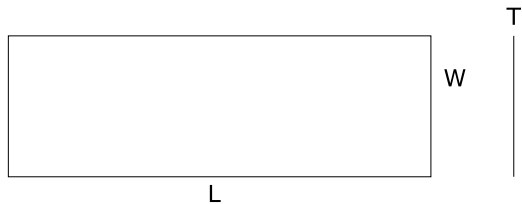

General Information

Series:	EFA
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions

Sheet Size	240x80mm
L	240mm NOM
W	80mm NOM
T	0.2mm NOM

Specifications

Temperature Range:	-40/+105C
Magnetic Permeability:	60 u At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.1 Atm TYP

Packaging Specifications

Weight:	12.7 g
---------	--------