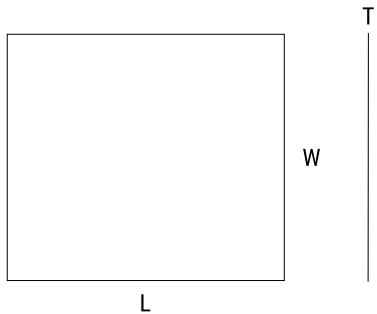


## KEMET, EFF4, Flex Suppressors, Noise Suppression

**Dimensions**

Sheet Size	120x120mm
L	120mm NOM
W	120mm NOM
T	0.1mm NOM

**Packaging Specifications**

Weight:	5.92 g
---------	--------

**General Information**

Series:	EFF4
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No.E176124, AEC-Q200
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

**Specifications**

Temperature Range:	-40/+125C
Magnetic Permeability:	140 $\mu$ At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.7 Atm TYP