


KEMET, M4, Flex Suppressors, RFID

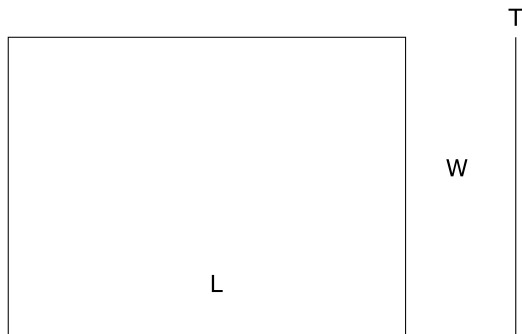

General Information

Series:	M4
Style:	Sheet
Description:	Flex Suppressor Halogen Free Type
Features:	High Magnetic Permeability Type, Low Magnetic Loss Type
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions

Sheet Size	90x70mm
L	90mm NOM
W	70mm NOM
T	0.2mm NOM

Specifications

Temperature Range:	-40/+105C
Magnetic Permeability:	40 u At 13.56MHz
Effective Frequency:	13.56 MHz Max
Resistance:	10 MOhms MIN
Specific Gravity:	3.1 Atm TYP

Packaging Specifications

Weight:	3.91 g
---------	--------