


KEMET, EFS, Flex Suppressors, Noise Suppression

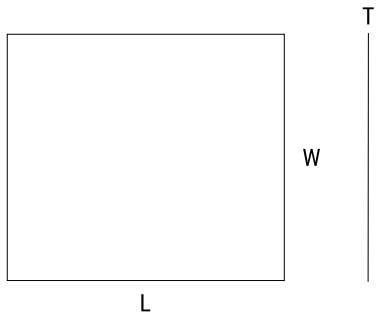

General Information

Series:	EFS
Style:	Sheet
Description:	Flex Suppressor Super High Frequency Type
Features:	Super High Frequency
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions

Sheet Size	120x120mm
L	120mm NOM
W	120mm NOM
T	0.5mm NOM

Specifications

Temperature Range:	-40/+105C
Magnetic Permeability:	10 u At 3MHz
Effective Frequency:	40 GHz Max
Resistance:	100 MOhms MIN
Specific Gravity:	4.5 Atm TYP

Packaging Specifications

Weight:	33.5 g
---------	--------