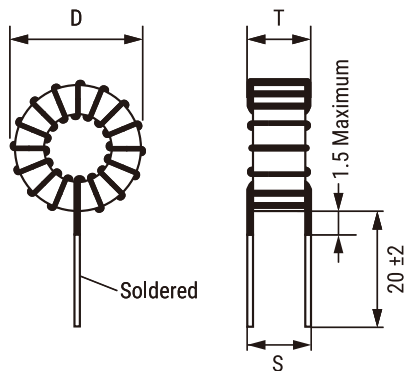


KEMET, SN, AC Line Filters, Normal Mode, 10 uH, MIN

**Dimensions**

D	8.5mm MAX
T	5.5mm MAX
LL	20mm +/-2mm
S	5mm NOM

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	6000
Weight:	800 mg

General Information

Series:	SN
Style:	Through-Hole
Features:	Compact Size
RoHS:	Yes
Miscellaneous:	15 (K) Temperature Rise Max.

Specifications

Inductance:	10 uH (0.1 MHz)
Inductance Tolerance:	MIN
Temperature Range:	-25/+105C
DC Resistance:	45 mOhms