


KEMET, SBT-01W, DC Line Filters, Common Mode, 60 uH, 35%

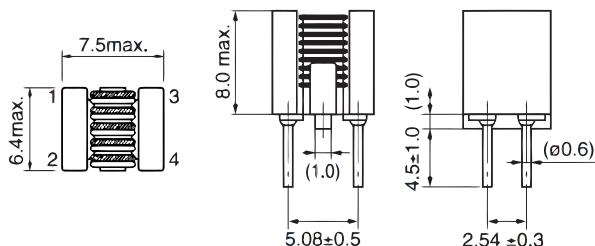

Dimensions

L	7.5mm MAX
W	6.4mm MAX
H	8mm MAX
LL	4.5mm +/-1mm
S	5.08mm +/-0.5mm

Packaging Specifications

Packaging:	Bulk, Box
Packaging Quantity:	100
Weight:	500 mg

General Information

Series:	SBT-01W
Style:	Through-Hole
RoHS:	Yes
Miscellaneous:	Inductance: 70mAmps (1kHz)

Specifications

Voltage DC:	50 VDC
Inductance:	60 uH
Inductance Tolerance:	35%
Temperature Range:	-25/+70C
DC Resistance:	45 mOhms

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.