

# PDMIKC5

## Professional Table Top Condenser Microphone

**PYLE**

PyleUSA.com

Please read this guide before operating this product. After you finish reading this guide, store it in a safe place for future reference.

### MAIN FEATURES

1. With audio compressing-expanding technology, the machine can lower noises and increase the dynamic range. It can also lower reecho.
2. Special tone key locked identity functions to avoid interference signal from outside open the mute system.
3. There are multiple noise detect circuit, multi circuits, So it has strong anti-jamming specialty.
4. Uniform cardioid pickup pattern isolates the main sound source and minimizes background noise
5. Effective, built-in spherical wind and pop filter.

### CAUTIONS


1. With audio compressing-expanding technology, the machine can lower noises and increase the dynamic range. It can also lower reecho.
2. Special tone key locked identity functions to avoid interference signal from outside open the mute system.
3. There are multiple noise detect circuit, multi circuits, so it has strong anti-jamming specialty.
4. Uniform cardioid pickup pattern isolates the main sound source and minimizes background noise
5. Effective built-in spherical wind and pop filter.

### TABLE MICROPHONE



- |                      |  |
|----------------------|--|
| 1. Cartridge         | 4. Power and Low Voltage Two Color Indicator |
| 2. Working Indicator | 5. Audio Output                              |
| 3. Switch            |  |

### SYSTEM

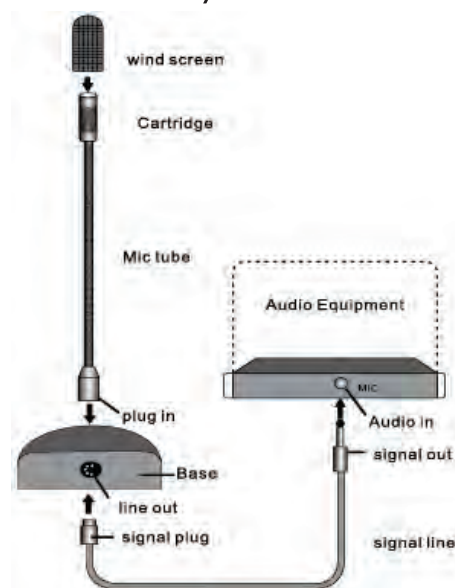

### USER GUIDE

#### HOW DO YOU OPERATE IT?

1. Insert a battery( 9V) with the correct polarity and connect the audio cable.
2. Adjust the volume of the amplifier to the minimum position.
3. Switch the power switch of the amplifier and meeting microphone, then adjust the volume of the amplifier slowly to desired level.
4. The best effective distance is about 20cm away the microphone's head .

#### ATTENTIONS:

1. The speaker will whistle if microphone is too near to the speaker or the volume of the amplifier is too high, take care of keep certain distance and to limit the volume of the amplifier otherwise damage maybe occur to the amplifier or the speaker.
2. Take out the battery if the microphone will not be used for a long time, the device may be damaged as the spillage of desgenerative battery.

### PROFESSIONAL TABLE TOP CONDENSER MICROPHONE GUIDE

- Cardioid Pickup Rejects Off-Axis Sound
- Durable Metal Tube And Bottom Base And PVC Plastic Construction
- Frequency Response: 40hz-16khz
- 200 Ohm Output Impedance
- Microphone Sensitivity: -40dB (+/-)2dB
- Reference Sound Receiving Distance: 20-80m
- Power Supply: Dc 9 Volt
- On/off Broadcasting Switch
- 26.2foot X 4.5mm Microphone Cable With 600 Outputs