


C-S

Non-Replaceable Probe - Epoxy Mount

Product Family: C-S

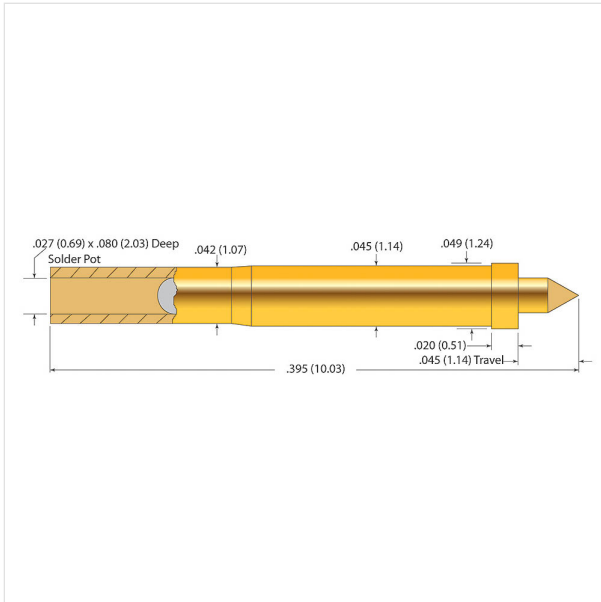

Mechanical:

Test Center (mil): 75

Test Center (mm): 1.91

Overall Length (mil): 395

Overall Length (mm): 10.03

Full Travel (mil): 45

Full Travel (mm): 1.14

Recommended Travel (mil): 30

Recommended Travel (mm): 0.76

Rec. Mounting Hole Size (mil): 46.5

Rec. Mounting Hole Size (mm): 1.18

Recommended Drill Size: 56

Thermal:

Max Operating Temp (°C): 150

Min Operating Temp (°C): -55

Electrical:

Current Rating (Amps): 5

Average DC Resistance lower than (mOhm): 30

Materials & Finishes:

Plunger Material: Heat-treated BeCu, Gold plated

Barrel Material: Brass, Gold plated

Ball Material: Stainless Steel, Gold plated

Springs

Force Type - Preload in oz (g) - Rec. Travel in oz (g) -

Spring Material

Standard - 0.50 (14.00) - 3.40 (96.00) - Stainless Steel, Gold plated

Additional information:


For more details, please contact us. marcom_ect-cpg@Xcerra.com

TIPS:

Tip Materials: BeCu

Tips:

C-S-C

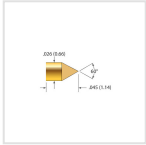

C-S-R

