


## P2662B

### Pylon Probe

Product Family: Pylon

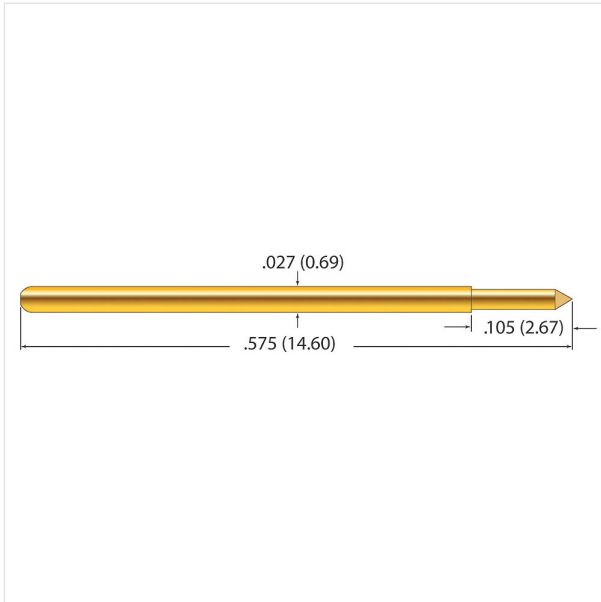

#### Mechanical:

**Test Center (mil):** 50

**Test Center (mm):** 1.27

**Overall Length (mil):** 575

**Overall Length (mm):** 14.60

**Full Travel (mil):** 68

**Full Travel (mm):** 1.73

**Recommended Travel (mil):** 50

**Recommended Travel (mm):** 1.27

#### Thermal:

**Max Operating Temp (°C):** 85

**Min Operating Temp (°C):** -55

#### Electrical:

**Current Rating (Amps):** 3

**Average DC Resistance lower than (mOhm):** 30

#### Materials & Finishes:

**Plunger Material:** Heat-treated BeCu, Gold plated over hard Nickel

**Barrel Material:** Phosphor Bronze, Gold plated

**Ball Material:** Stainless Steel

#### Springs

Force Type - Preload in oz (g) - Rec. Travel in oz (g) -

Spring Material

Standard - 1.00 (28.00) - 1.80 (51.00) - BeCu, Silver plated

Alternate - 0.50 (14.00) - 2.50 (71.00) - BeCu, Silver plated

#### Body Type

Straight

Pylon Bend

#### Additional information:


Use tool RIT-0-0 for installation

**TIPS:**


Tip Materials: BeCu, Gold plated

**Tips:**

**P2662-1C**

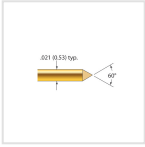


**P2662-1Q**

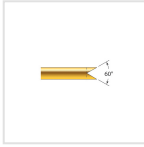

**P2662-1R**




**P2662-2V**

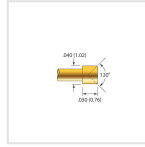


**Related Products:**


**PR261-0**

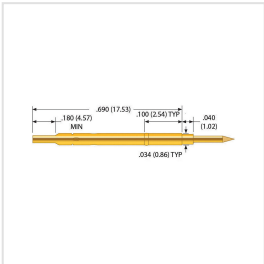


**PR261-0F**

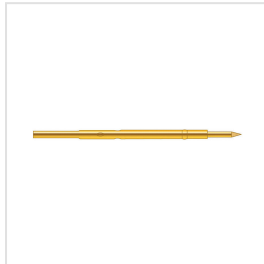

**PR261-1**

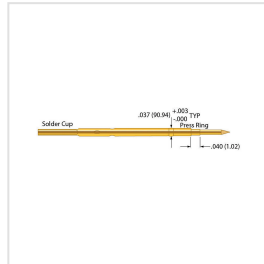

**PR261-1F**

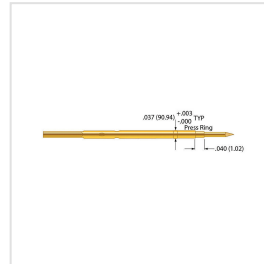

**RIT-0-0**

