


P2663

Pylon Probe

Product Family: Pylon

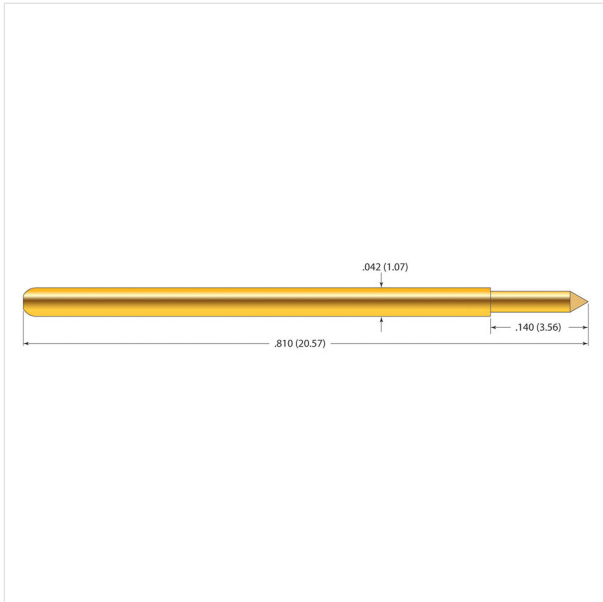

Mechanical:

Test Center (mil): 75

Test Center (mm): 1.91

Overall Length (mil): 810

Overall Length (mm): 20.57

Full Travel (mil): 90

Full Travel (mm): 2.29

Recommended Travel (mil): 67

Recommended Travel (mm): 1.70

Thermal:

Max Operating Temp (°C): 150

Min Operating Temp (°C): -55

Electrical:

Current Rating (Amps): 3

Average DC Resistance lower than (mOhm): 10

Materials & Finishes:

Plunger Material: Hardened BeCu, Gold plated

Barrel Material: Phosphor Bronze, Gold plated

Ball Material: Stainless Steel

Springs

Force Type - Preload in oz (g) - Rec. Travel in oz (g) -

Spring Material

Alternate - 1.00 (28.00) - 2.00 (57.00) - Stainless Steel

Standard - 1.50 (42.00) - 3.30 (94.00) - Stainless Steel

Body Type

Straight


Pylon Bend

TIPS:


Tip Materials: BeCu, Gold plated, Steel

Tips:


P2663-1C

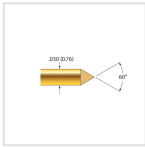


P2663-1P

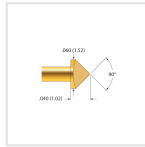


P2663-1R

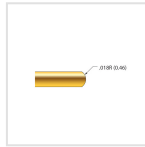

P2663-1V

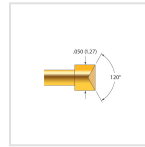

P2663-1W

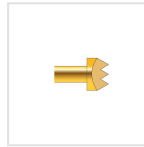


P2663-3R




Related Products:

S2663-1ED

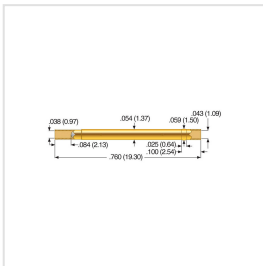

S2663-1ETD

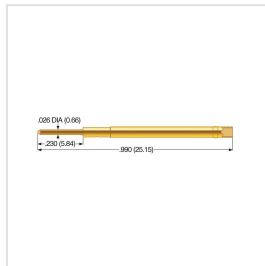

S2663-1EWWD

