


P3158

Pylon Probe

Product Family: Pylon

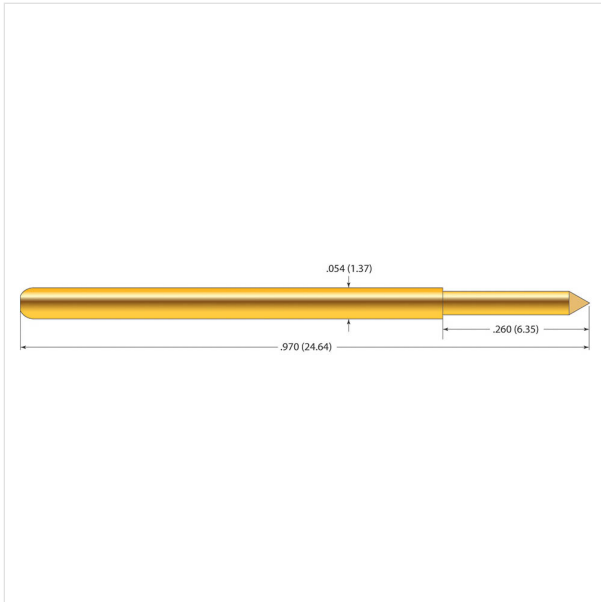

Mechanical:

Test Center (mil): 100

Test Center (mm): 2.54

Overall Length (mil): 970

Overall Length (mm): 24.64

Full Travel (mil): 170

Full Travel (mm): 4.32

Recommended Travel (mil): 114

Recommended Travel (mm): 2.90

Thermal:

Max Operating Temp (°C): 105

Min Operating Temp (°C): -55

Electrical:

Current Rating (Amps): 8

Average DC Resistance lower than (mOhm): 10

Materials & Finishes:

Plunger Material: Heat-treated BeCu or Steel, Gold plated over hard Nickel

Barrel Material: Phosphor Bronze, Gold plated

Ball Material: Stainless Steel

Springs

Force Type - Preload in oz (g) - Rec. Travel in oz (g) -

Spring Material

Standard - 2.70 (72.00) - 6.90 (196.00) - Music Wire

Alternate - 1.30 (37.00) - 2.80 (79.00) - Music Wire

Body Type

Straight

Pylon Bend

Additional information:


Use ARIT-25 tool for installation

TIPS:

Tip Materials: BeCu, Gold plated, Steel

Tips:


P3158-1Q

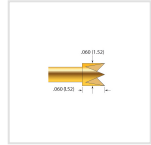

P3158-1R




P3158-1V

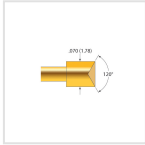


P3158-1W



P3158-2Q

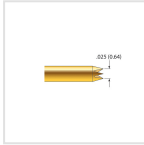


P3158-3C

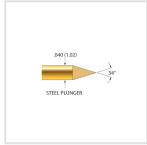


Related Products:


PR541-0

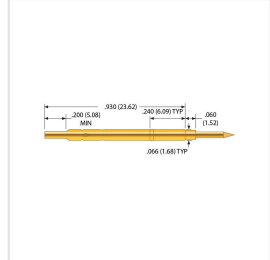


PR541-0F

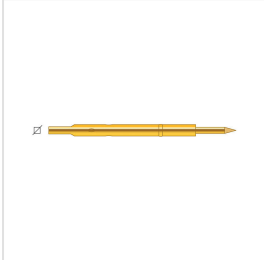


PR541-1

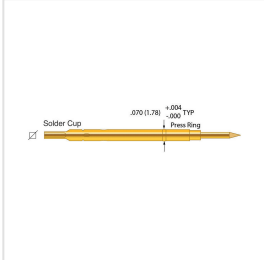


PR541-1F

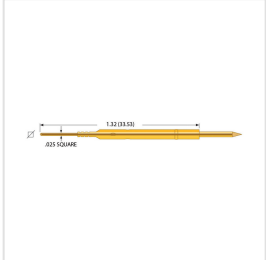


PR541-2

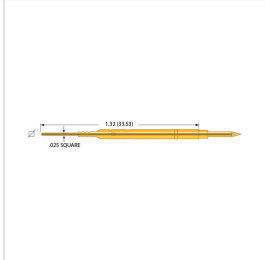


PR541-2F

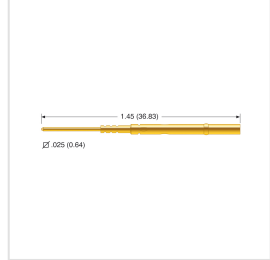

PR541-3

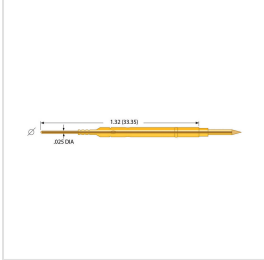

PR541-3F

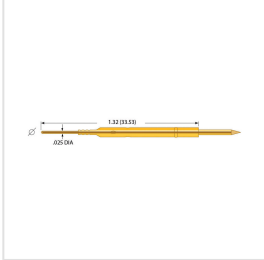

ARIT-25

