


P5160

Pylon Probe

Product Family: Pylon

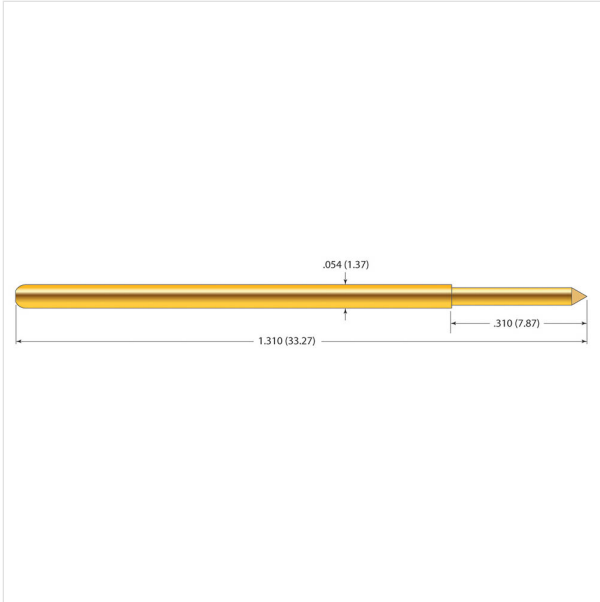

Mechanical:

Test Center (mil): 100

Test Center (mm): 2.54

Overall Length (mil): 1,310

Overall Length (mm): 33.27

Full Travel (mil): 230

Full Travel (mm): 5.84

Recommended Travel (mil): 167

Recommended Travel (mm): 4.24

Thermal:

Max Operating Temp (°C): 105

Min Operating Temp (°C): -55

Electrical:

Current Rating (Amps): 8

Average DC Resistance lower than (mOhm): 10

Materials & Finishes:

Plunger Material: Heat-treated BeCu, Gold plated over hard Nickel

Barrel Material: Phosphor Bronze, Gold plated

Ball Material: Stainless Steel

Springs

Force Type - Preload in oz (g) - Rec. Travel in oz (g) -

Spring Material

Standard - 2.50 (71.00) - 6.50 (184.00) - Music Wire

Alternate - 1.70 (48.00) - 3.50 (99.00) - Music Wire

Elevated - 2.50 (71.00) - 8.20 (232.00) - Music Wire

Body Type

Straight

Pylon Bend

Additional information:


Use ARIT-25 tool for installation

TIPS:

Tip Materials: BeCu, Gold plated, Steel

Tips:


P5160-1Q

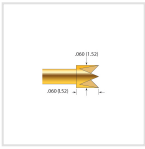


P5160-1R




P5160-1V

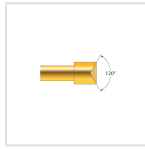


P5160-2C

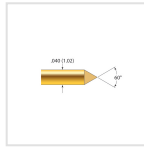


P5160-2W

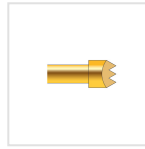

P5160-3C

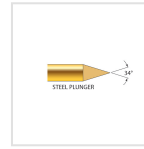


P5160-3P

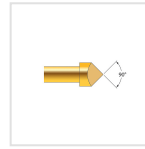


Related Products:


PR54-0

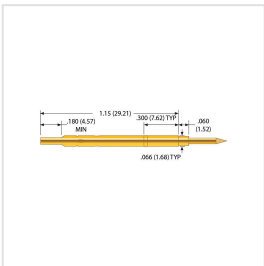


PR54-0F

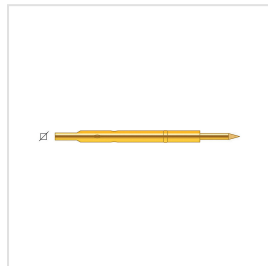


PR54-1

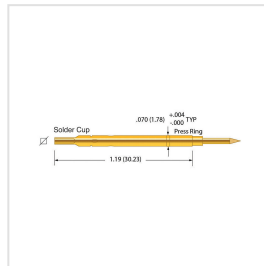


PR54-1F

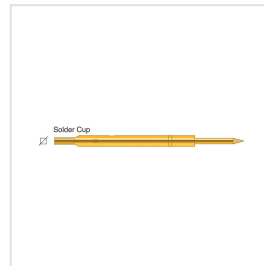


PR54-2

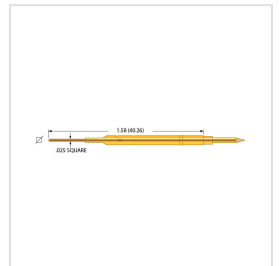


PR54-2F

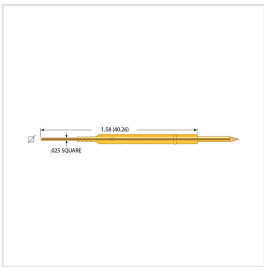

PR54-3

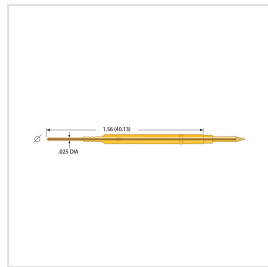

PR54-3F

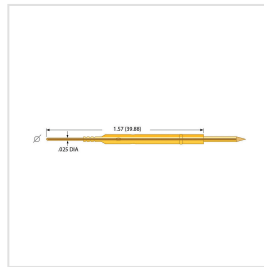

ARIT-25

