


P2757

Replaceable Probe

Product Family: Pylon

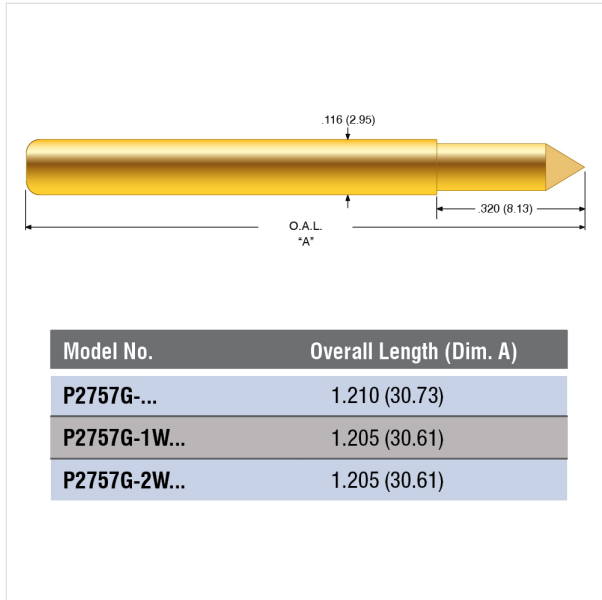

Springs

Force Type - Preload in oz (g) - Rec. Travel in oz (g) -

Spring Material

Standard - 2.00 (57.00) - 4.00 (113.00) - Stainless Steel

Alternate - 3.50 (99.00) - 6.85 (194.00) - Stainless Steel

Body Type

Straight

Pylon Bend

Mechanical:

Test Center (mil): 187

Test Center (mm): 4.75

Overall Length (mil): 1,210

Overall Length (mm): 30.73

Overall Length Remark: Tip 2C: 1140 mil (28.96 mm)

Tip 1W: 1205 mil (30.61 mm) Tip 2W: 1205 mil (30.61 mm)

Full Travel (mil): 230

Full Travel (mm): 5.84

Recommended Travel (mil): 167

Recommended Travel (mm): 4.24

Thermal:

Max Operating Temp (°C): 150

Min Operating Temp (°C): -55

Electrical:

Current Rating (Amps): 20

Average DC Resistance lower than (mOhm): 10

Materials & Finishes:


Plunger Material: Heat-treated BeCu, Gold plated over hard Nickel

Barrel Material: Phosphor Bronze, Gold plated

Ball Material: Stainless Steel

TIPS:
Tip Materials: BeCu, Gold plated
Tips:


P2757-1C

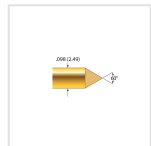


P2757-1R




P2757-1V

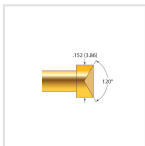

P2757-1W

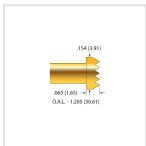

P2757-2W

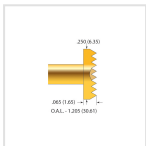


P2757-3W




Related Products:

S2757-2ED

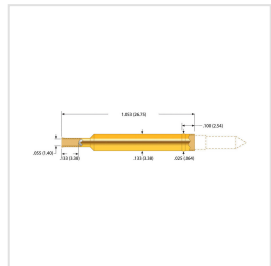

S2757-2ETD

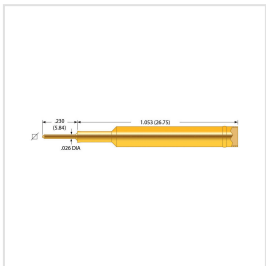

S2757-2EWWD

