

# RJ45 Punch Down Plugs

## Cat6 and Cat6A Ethernet Solutions


Stewart Connector's RJ45 punch down plugs are time-saving solutions for Ethernet connections that require field terminations. The applications for Stewart's RJ45 punch down plugs include data, telecom, wireless, POE applications, and industrial equipment connections.

### Features

- The RJ45 Punch Down Plugs are designed for quick and easy field terminations
- Cat6 punch down plug is suitable for use in 1G Base-T networks and the Cat6A for 10G Base-T networks
- Contact designed for use on solid or stranded conductor cable
- 50 micro-inches of gold plating on contacts for increased cycle life
- Easy to use color coded conductor pre-load wire manager
- Terminates 23-26 AWG cable with a diameter over the insulation of up to 1.6 mm (.063")
- Accepts an overall cable OD of 6mm (.236") to 8mm (.315")

### Benefits

- Suitable for both shielded and unshielded applications
- Compression strain relief
- No termination tooling required
- Adequate for Power Over Ethernet applications
- Utilizes robust zinc die-cast housings and latch protectors
- Each plug kits includes termination instructions

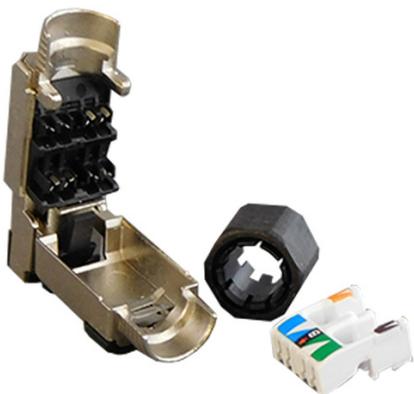

Part Number	LAN Category	Wire Gauge	Cable OD
SS-39300-001	Cat6	23-26 AWG	6mm-8mm (.236"-.315")
SS-39300-002	Cat6A	23-26 AWG	6mm-8mm (.236"-.315")