

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0511630400](#)
Status: **Active**
Description: 2.50mm Pitch Wire-to-Board Receptacle Housing, Positive Lock, with Retainer, 4 Circuits, Glow-Wire Capable, Natural

Documents:

[3D Model](#) [Product Specification PS-51163-002-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification 511630000-PS-000 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [51163](#)
 Application Signal, Wire-to-Board
 Product Name Mini-Lock
 UPC 800753325579


Physical

Circuits (maximum) 4
 Color - Resin Natural
 Flammability 94V-0
 Gender Receptacle
 Glow-Wire Capable Yes
 Keying to Mating Part None
 Material - Resin Polyester
 Net Weight 547.800/mg
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.50mm
 Stackable No
 Temperature Range - Operating -40° to +105°C

Material Info

Reference - Drawing Numbers

Product Specification 511630000-PS-000, PS-51163-002-001
 Sales Drawing SD-51163-**00, SD-51163-001

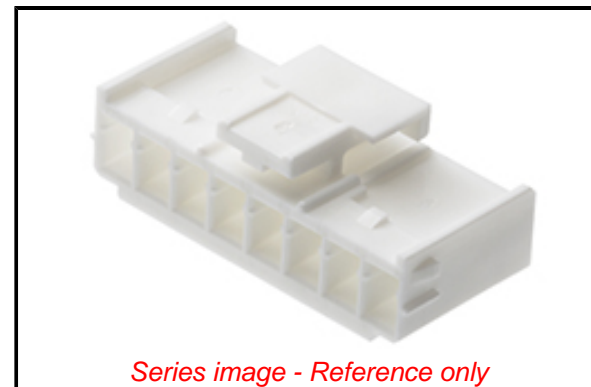

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[51163 Series](#)

Mates With

[53375](#) , [53426](#) , [53517](#)

Use With

[50351](#) , [50752](#) , [51164](#)