




Produktname | *Product name*: T300F
 Artikelnummer | *Part Number*: 1600-0202
 Anfragenummer | *Inquiry Number*: AN201530
 Ersteller / Datum | *Creator / Date*: LHE / 2018-02-20

Version	Change	Date	Name
V1	LED Typ	2018-06-25	LHE
V0	---	2018-02-20	LHE

Template name: Light (Non-Rechargeable), Template version: V14

Leuchte / light

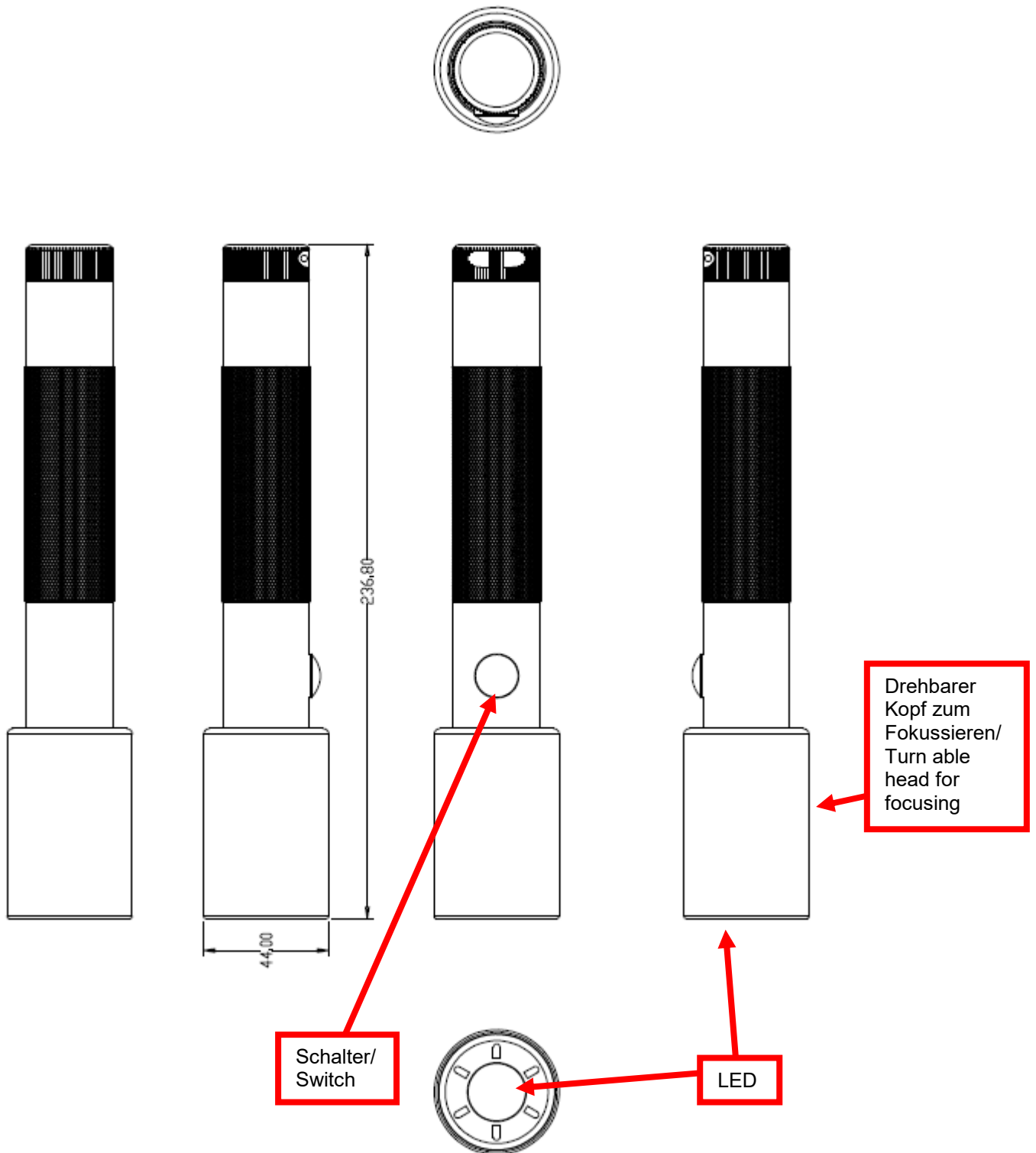

Technische Daten der Leuchte / Technical data of the light:



Haupt-LED-Leuchtmittel:	XP-G3 5W Cree® LED	Main LED illuminant:	XP-G3 5W Cree® LED
Optisches System der Haupt-LED	Fokussierbar	Optical system of main LED	Focus able
Optisches System	Konvexlinse	Optical system	convex lens
Schalterfunktion:	1. 100% LED Leistung	Switch function:	1. 100% LED power
	2. Aus		2. Off
	3. 40% LED Leistung		3. 40% LED power
	4. Aus		4. Off

Lichtstrom: [Lumen]	ca. 320lm	ca. 130lm	Luminous flux (light output): [Lumen]	approx. 320lm	ca. 130lm
Leuchtdauer:	ca. 4h 15min	ca. 7h	Run time:	approx. 4h 15min	ca. 7h
Leuchtweite:	ca. 110m	ca. 65m	Beam distance:	approx. 110m	ca. 65m
Maximale Beleuchtungsstärke: [Lux]	ca. 2500lx (Abstand: 1m)	ca. 850lx (Abstand: 1m)	Peak beam illuminance: [Lux]	approx. 2500lx (Distance: 1m)	ca. 850lx (Abstand: 1m)
Risikogruppe (EN 62471; Bewertet nach DIN IEC/TR 62778 Anhang C.2)	2		Risk group (EN 62471; Assessed with TR 62778 Annex C.2)	2	

Geeignete Batterietypen:	2x Baby C 1.5V Batterien (Alkaline; LR14/AM-2/MN1400)	Suitable batteries types:	2 x Baby C 1.5V batteries (Alkaline; LR14/AM-2/MN1400)
Sichere Fallhöhe	1m	Safe drop height	1m
Gehäusematerial:	Aluminium	Housing material:	Aluminium
Betriebstemperatur:	-10°C...25°C	Operating temperature:	-10°C...25°C
Lagertemperatur:	-10°C...50°C (Nur Alkaline Batterie/Batterien) -20°C...70°C (Nur Lampe)	Storage temperature:	-10°C...50°C (Alkaline battery/batteries only) -20°C...70°C (Torch only)
Empfohlene Lagerbedingungen: (Nur Alkaline Batterien)	Temperatur: 5..25°C Luftfeuchtigkeit: 45..75%	Recommended storage conditions: (Alkaline batteries only)	Temperature: 5...25°C Rel. humidity: 45...75 %
Approbationen:	CE	Approvals:	CE
Gewicht:	434 g (Lampe mit Batterien) 296 g (Lampe)	Weight:	434 g (lamp with batteries) 296 g (lamp)
Lieferumfang:	- 2 x Batterien, wie oben beschrieben, aber mit ANSMANN Redline Label - Handschlaufe	Included in delivery:	- 2 x batteries, as described above, but with ANSMANN Redline label - Lanyard
Verpackung:	Blister-Verpackung	Package:	Blister shell