


Mod. 5221 B

COPOLYMER POLYPROPYLENE WATERPROOF CASE



Metric mm-Kg-C°

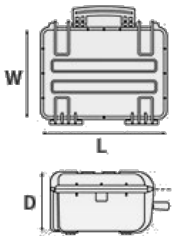

INTERNAL DIMENSIONS

| | |
|----------|--------|
| L Length | 520 mm |
| W Width | 285 mm |
| D Depth | 205 mm |
| Lid | 55 mm |
| Base | 150 mm |


EXTERNAL DIMENSIONS

| | |
|----------|--------|
| L Length | 550 mm |
| W Width | 350 mm |
| D Depth | 225 mm |

OTHER DATA

| | |
|-------------------------|----------------------|
| Weight empty | 3.90 Kg |
| Weight with foam | 4.50 Kg |
| Weight with custom foam | Kg |
| Volume | 30,3 lt |
| Buoyancy | 20 Kg/max |
| Operating temperature | °C min -33 / max +90 |

Imperial in-lbs-F°

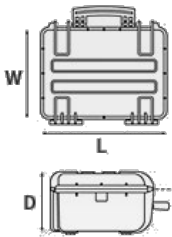

INTERNAL DIMENSIONS

| | |
|----------|-----------|
| L Length | 20 1/2 in |
| W Width | 11 1/4 in |
| D Depth | 8 1/16 in |
| Lid | 2 3/16 in |
| Base | 5 7/8 in |

EXTERNAL DIMENSIONS

| | |
|----------|-----------|
| L Length | 21 5/8 in |
| W Width | 13 3/4 in |
| D Depth | 8 7/8 in |

OTHER DATA

| | |
|-------------------------|-------------------------|
| Weight empty | 8.59 lbs |
| Weight with foam | 9.92 lbs |
| Weight with custom foam | lbs |
| Volume | 8 gal |
| Buoyancy | 44.09 lbs/max |
| Operating temperature | °F min -27.4 / max +194 |