




907-XXX2 SERIES

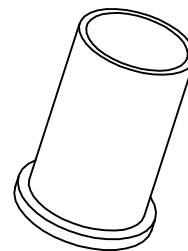

PART NUMBER	CRIMP BARREL WIRE SIZE	WIRE SIZE AWG	WIRE SIZE SQ MM	A +.0020 -.0035	B +.0025 -.0030	C ±.015	D ±.005
907-2005-XXX	20	26	0.14	.023	.042	.120	.015
907-2011-XXX	20	26	0.14	.023	.042	.120	.015
907-2010-XXX	20	24-30	0.25-0.05	.027	.042	.120	.015
907-2012-XXX	16		0.12	.033	.063	.230	.015
907-2013-XXX	16	26	0.14	.033	.063	.230	.015
907-2016-XXX	16	24	0.25	.035	.063	.230	.015
907-2020-XXX	16	22-24	0.34	.035	.063	.230	.015
907-2021-XXX	16	22	0.34	.043	.063	.230	.015
907-2022-XXX	16	22	0.34	.035	.063	.190	.015
907-2025-XXX	16	22	0.34	.043	.059	.149	.015
907-2030-XXX	16	20	0.50	.046	.063	.230	.015
907-2037-XXX	14	22	0.34	.043	.070	.230	.015
907-2038-XXX	12	20	0.50	.046	.094	.221	.015
907-2039-XXX	12	18	0.75	.065	.094	.221	.015
907-2040-XXX	12	16	1.50	.069	.094	.230	.015
907-2041-XXX	12	18	0.75	.054	.094	.221	.015
907-2043-XXX	6.0 MM		1.50	.068	.140	.230	.015
907-2045-XXX	6.0 MM		2.50	.086	.140	.230	.015
907-2049-XXX	8	18	0.75	.065	.173	.380	.031
907-2050-XXX	8	16	1.50	.069	.173	.380	.031
907-2051-XXX	8	16	1.50	.072	.173	.422	.031
907-2053-XXX	8	14	2.50	.086	.173	.422	.031
907-2055-XXX	8	14	2.50	.086	.173	.422	.031
907-2056-XXX	8	12	3.00	.111	.173	.380	.031
907-2060-XXX	8	12	3.00	.111	.173	.380	.031
907-2061-XXX	8	12	3.00	.111	.173	.380	.031
907-2062-XXX	8	12	3.00	.111	.178	.380	.031
907-2068-XXX	8	10	6.00	.126	.175	.380	.031
907-2070-XXX	8	10	6.00	.136	.173	.380	.031
907-2071-XXX	8	10	6.00	.144	.173	.380	.031
907-2072-XXX	8	10	6.00	.136	.173	.422	.031
907-2073-XXX	8SP	12	3.00	.100	.130	.422	.031
907-2077-XXX	10 MM	12	3.00	.100	.173	.422	.031
907-2080-XXX	6	10	6.0	.136	.225	.700	.031
907-2090-XXX	6	9		.155	.225	.700	.031
907-2100-XXX	6	8	10.0	.185	.225	.700	.031
907-2102-XXX	16 MM		2.5	.086	.240	.480	.031
907-2103-XXX	16 MM		4.0	.111	.240	.480	.031
907-2105-XXX	16 MM	10	6.0	.144	.240	.480	.031
907-2107-XXX	16 MM	8	10.0	.185	.240	.480	.031
907-2108-XXX	4	10	6.0	.136	.272	.373	.031
907-2109-XXX	4	10	6.0	.144	.272	.380	.031
907-2110-XXX	4	8	10.0	.185	.272	.380	.031

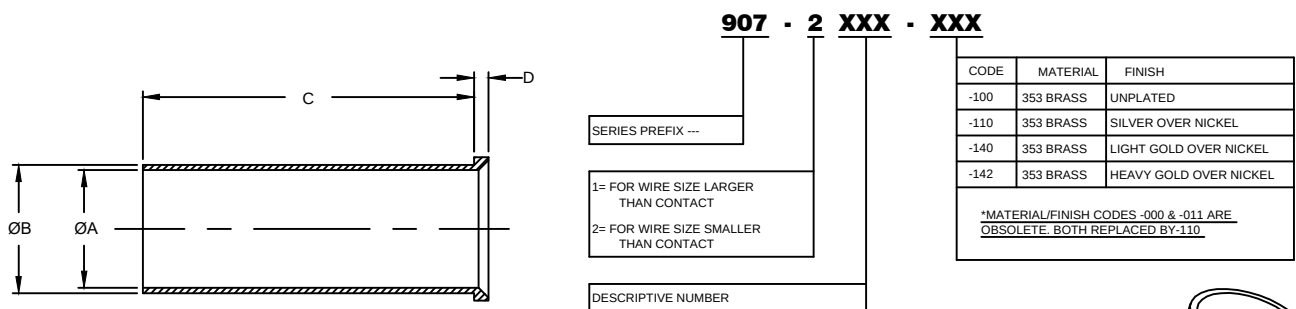

907-XXX2 SERIES

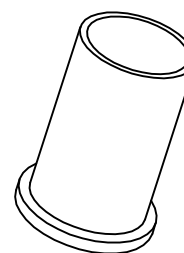

PART NUMBER	CRIMP BARREL WIRE SIZE	WIRE SIZE AWG	WIRE SIZE SQ MM	A +.002 -.003	B +.002 -.003	C ±.015	D ±.005
907-2111-XXX	4	8	10.0	.185	.272	.700	.031
907-2112-XXX	4	8	10.0	.197	.272	.380	.031
907-2113-XXX	4	5	15.0	.197	.272	.380	.031
907-2114-XXX	4	8	10.0	.197	.272	.380	.031
907-2117-XXX	4	6	16.0	.225	.272	.422	.031
907-2118-XXX	4	12	4.0	.101	.272	.240	.031
907-2119-XXX	4	6	2.5	.235	.272	.700	.031
907-2120-XXX	4	6	16.0	.225	.272	.380	.031
907-2130-XXX	4	6	16.0	.225	.272	.700	.031
907-2140-XXX	4	5	15.0	.250	.272	.700	.031
907-2150-XXX	4	5	15.0	.242	.272	.380	.031
907-2152-XXX	4	5	15.0	.240	.272	.440	.031
907-2153-XXX	4	6	16.0	.244	.272	.440	.031
907-2154-XXX	4	313 MCM		.730	.823		
907-2155-XXX	25 MM	10	6.0	.144	.300	.480	.031
907-2156-XXX	25 MM	6	16.0	.244	.300	.480	.031
907-2158-XXX	2	4	25.0	.281	.347	.480	.031
907-2159-XXX	35 MM	25 MM		.305	.347	.480	.031
907-2160-XXX	1	6	16.0	.225	.396	.700	.031
907-2165-XXX	1	6	16.0	.250	.396	.700	.031
907-2168-XXX	1	4		.299	.396	.700	.031
907-2170-XXX	1	2	35.0	.359	.396	.700	.031
907-2171-XXX	50 MM	4	25.0	.300	.415	.600	.031
907-2172-XXX	1/0	10	6.0	.136	.444	.644	.031
907-2173-XXX	1/0	8	9.0	.185	.444	.644	.031
907-2174-XXX	1/0	8	10.0	.197	.444	.644	.031
907-2175-XXX	1/0	6	16.0	.225	.444	.644	.031
907-2176-XXX	1/0	6	16.0	.244	.444	.536	.031
907-2178-XXX	1/0		20.0	.195	.444	.536	.031
907-2179-XXX	1/0	4	25.0	.307	.444	.536	.031
907-2180-XXX	1/0	4	25.0	.299	.444	.536	.031
907-2181-XXX	1/0	8	10.0	.197	.444	.500	.031
907-2182-XXX	1/0	2	35.0	.244	.444	.500	.031
907-2183-XXX	1/0	4	25.0	.307	.444	.500	.031
907-2184-XXX	1/0	2	35.0	.354	.444	.500	.031
907-2185-XXX	1/0		50.0	.421	.444	.500	.031
907-2186-XXX	1/0	2	35.0	.359	.444	.664	.031
907-2187-XXX	1/0	4	25.0	.282	.444	.664	.031
907-2188-XXX	1/0	4	25.0	.282	.444	.536	.031
907-2190-XXX	1/0	2	35.0	.359	.444	.536	.031
907-2210-XXX	1/0	2	35.0	.417	.444	.536	.031
907-2200-XXX	1/0	1	50.0	.390	.444	.536	.031
907-2201-XXX	50 MM	2	35.0	.354	.410	.500	.031
907-2202-XXX	1/0		50.0	.421	.444	.536	.031
907-2203-XXX	2/0	2	35.0	.359	.491	.528	.031
907-2204-XXX	2/0	4	25.0	.307	.491	.528	.031
907-2205-XXX	2/0	2/0	70.0	.440	.491	.528	.031
907-2206-XXX	2/0		50.0	.421	.491	.528	.031
907-2210-XXX	70 MM	4	25.0	.307	.491	.500	.031
907-2211-XXX	70 MM		50.0	.421	.491	.500	.031
907-2207-XXX	95 MM	2/0	70.0				
907-2218-XXX	4/0	2/0	70.0	.500	.615	.700	.031
907-2219-XXX	4/0	2	35.0	.560	.629	.700	.031
907-2220-XXX	4/0	2/0	70.0	.500	.629	.700	.031
907-2221-XXX	4/0	3/0	95.0	.564	.629	.700	.031
907-2230-XXX	150 MM	2/0	70.0	.500	.629	.700	.031
907-2240-XXX	190 MM	4/0	107.0	.641			
907-2250-XXX	DIN500	6	16.0	.244			
907-2253-XXX	DIN500	2	35.0	.354			

