


Neo-Light Dual Color LED Task-Lamp

-Year
3

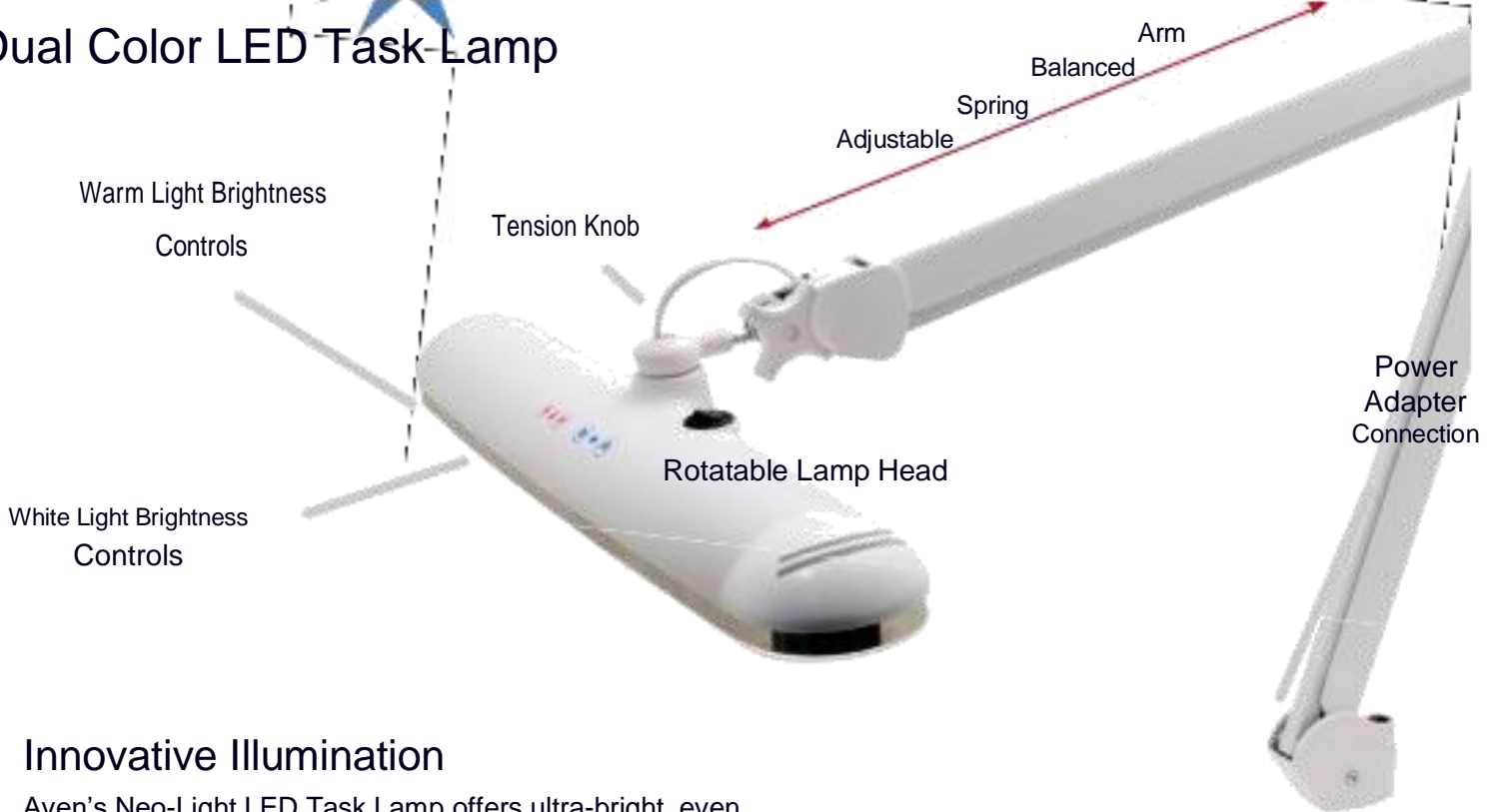

Innovative Illumination

Aven's Neo-Light LED Task Lamp offers ultra-bright, even illumination for your work bench. This modern, innovative design features 60 energy efficient LEDs with touch-sensitive buttons to control brightness and color temperature. Illuminate using warm light, white light, or both!

- Use the 30 warm LEDs, 30 white LEDs, or both!
- Brightness adjustment via touch-sensitive buttons
- Sleek, modern design
- Arm length approximately 36-inches

Perfect for a wide range of tasks



NEO-LIGHT DUAL COLOR LED TASK LAMP

| | |
|-----------------------|--|
| SKU | 26535 |
| BRIGHTNESS ADJUSTMENT | Via touch-sensitive buttons |
| LUMENS | Max 980lm |
| REACH | Approx. 36in |
| COLOR TEMPERATURE | 3500K-6500K |
| ILLUMINATION | 30 white and 30 warm LEDs |
| POWER SUPPLY | Input: 100-240V AC 50~60Hz Output: 20V |
| ACCESSORIES INCLUDED | Table clamp, power supply |