
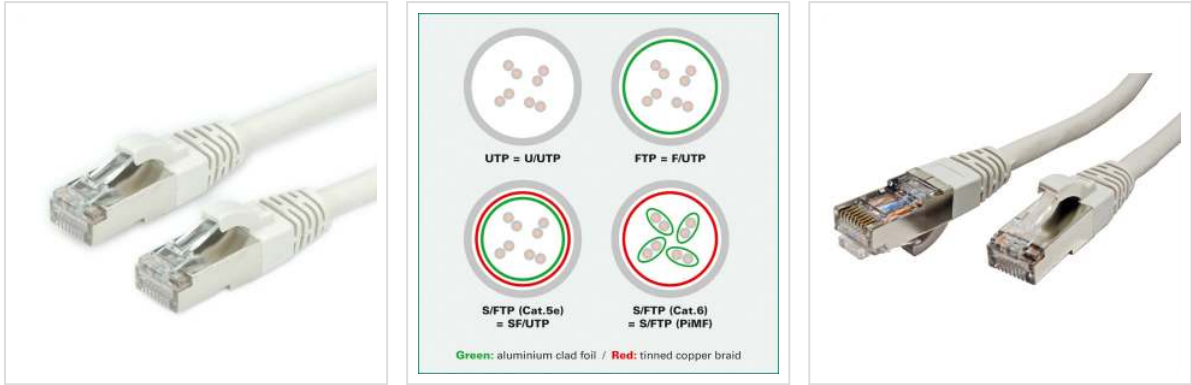


ROLINE S/FTP Cable (Cat.7), with RJ-45 connectors (500 MHz), LSOH, grey, 1.0 m

Product No.	21.15.0851	 Designed for Professionals
Manufacturer	ROLINE	
Manufacturer No.	21.15.0851	
EAN (single piece)	7611990110650	



Cat.6A

S/FTP

LSOH

The right solution for a network connection with data transfer rate up to 10 Gbit/s, at a frequency of 500 MHz

- Patch cord for networking connections between devices
- Prepared shielded Twisted Pair cable (PiMF) with Shielded RJ-45 connectors on both ends
- Durable due to moulded kink protection
- Flexible cable, suitable for narrow bending
- Impedance: 100 Ohm
- Colour: grey
- Contact settings 1:1, in accordance with the EIA/TIA 568 standard
- Construction: 8 lines + pairs shielded with aluminium foil, complete shielding in tinned copper braid

Technical specifications	
Manufacturer	ROLINE
Product group	Twisted Pair Cable
Product type	S/FTP Patchcord

Colour	grey
Length	1 m
Shield type	SFTP
Transfer quality	Cat6A / Class EA
Impedance	100 Ohm
Quantity of wires	8
Conductor type	Wire
Crossed	No
Colour (Spout)	grey
Cable LSOH	Yes
Side 1 Connector Type	RJ-45
Side 1 Connector Gender	Male
Side 2 Connector Type	RJ-45
Side 2 Connector Gender	Male
Connector Type RJ45	Standard