

BRUSHLESS DC FAN


F17FA

FEATURES


- 17 x 17 x 5 mm miniature fan.
- Proprietary impeller design provides high air flow and quiet operation. (0.01m³/min, 5dB(A) at 7000rpm)

APPLICATIONS

- Video equipments
- Information systems
- Telecommunication equipments

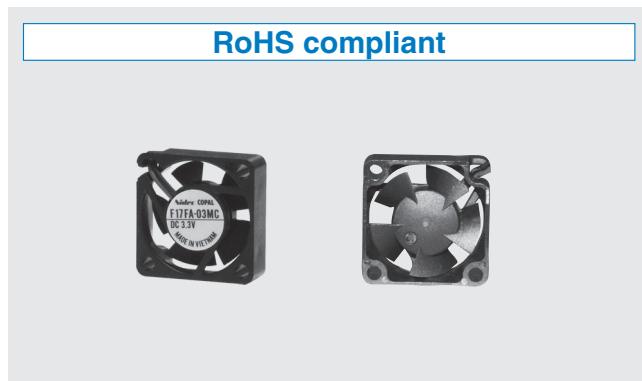

PART NUMBER DESIGNATION

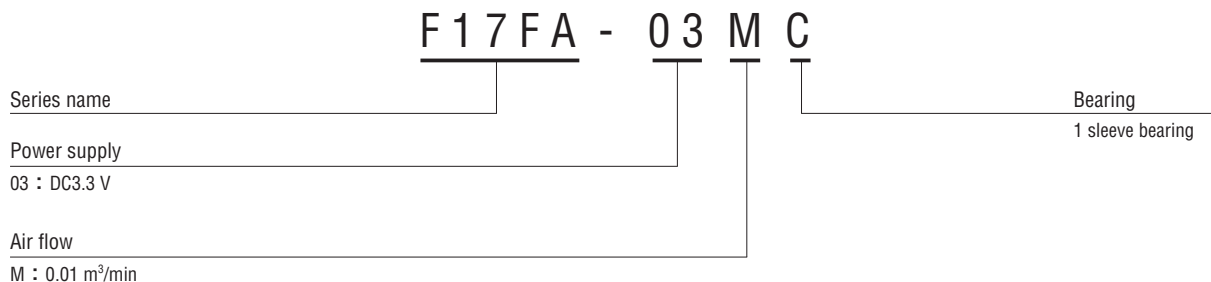

LIST OF PART NUMBERS

| Power supply | Part number |
|--------------|-------------|
| DC3.3 V | F17FA-03MC |

※ Verify the above part numbers when placing orders.

F17FA


MINIATURE BRUSHLESS DC FAN MOTORS

STANDARD SPECIFICATIONS

| Item | F17FA-03MC |
|---------------------|----------------------------|
| Rated voltage | DC3.3 V |
| Voltage range | 3.1 ~ 3.5 V |
| Rated current | 0.07 A |
| Rotating speed | 7000 min ⁻¹ |
| Air flow | 0.01 m ³ /min |
| Static pressure | 6 Pa |
| Noise | 5 dB (A) |
| Use environment | 0 ~ +60 °C (35 ~ 85 %RH) |
| Storage environment | -10 ~ +70 °C (35 ~ 85 %RH) |
| Net weight | Approx. 1.5 g |

※ The specifications above are typical values measured on the conditions of no-loading running with rated voltage in the circumstances of 25 °C ± 2 °C, 35~ 85 %RH. Please contact us if you would liketo check the specifications in different circumstances.

AIR FLOW PERFORMANCE CURVES

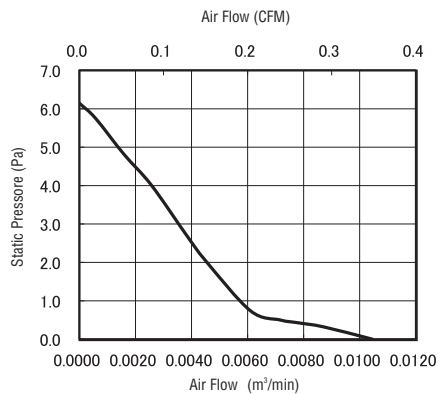

※ Data in our measuring instrument

OUTLINE DIMENSIONS

(Unit: mm)

