


KEMET, SBCP-80HY, Power, 0.01 H, 10%, 5mm

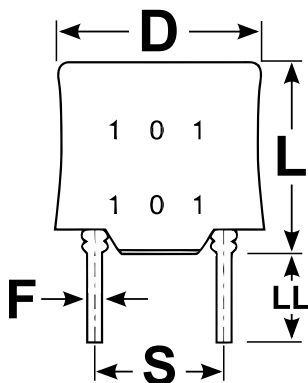

**Dimensions**

D	9.5mm MAX
L	11mm MAX
S	5mm +/-0.5mm
LL	3.5mm +1/-0.5mm
F	0.6mm NOM

**Packaging Specifications**

Weight:	2.27 g
Packaging:	Bulk
Packaging Quantity:	4000

**General Information**

Series:	SBCP-80HY
Style:	Through-Hole
Description:	Radial Leaded, Ferrite Power Inductors
Features:	DC-DC Converters, Nickel-Zinc (NiZn) Ferrite Core
RoHS:	Yes
Lead:	Wire Leads
Core:	Ferrite

**Specifications**

Inductance:	10000 uH (0.01 MHz)
Inductance Tolerance:	10%
Temperature Range:	-20/+105C
Shielded:	No
Current:	0.1 Amps
DC Resistance:	19.1 Ohms