


AxiMax 400 Comm C0G, Ceramic, 1000 pF, 5%, 50 VDC, C0G, AxiMax, Commercial Standard

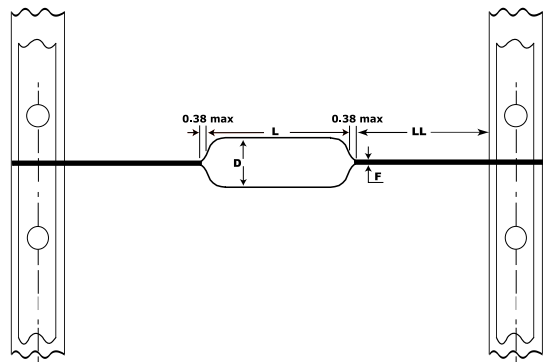

**Dimensions**

D	2.41mm MAX
L	4.32mm MAX
LL	25.4mm MIN
F	0.51mm +0.025/-0.076mm

**Packaging Specifications**

Packaging:	T&R, 305mm
Packaging Quantity:	5000

**General Information**

Supplier:	KEMET
Series:	AxiMax 400 Comm C0G
Description:	AxiMax, Commercial Standard
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A
Halogen Free:	Yes

**Specifications**

Capacitance:	1000 pF
Capacitance Tolerance:	5%
Voltage DC:	50 VDC
Dielectric Withstanding Voltage:	125 V
Temperature Range:	-55/+125C
Temperature Coefficient:	C0G
Dissipation Factor:	0.1% 25C
Aging Rate:	0% Loss/Decade Hour
Insulation Resistance:	100 GOhms