


KPS SMD Auto X7R, Ceramic, Commercial Grade, 2.2 uF, 10%, 50 VDC, X7R, 2220-1

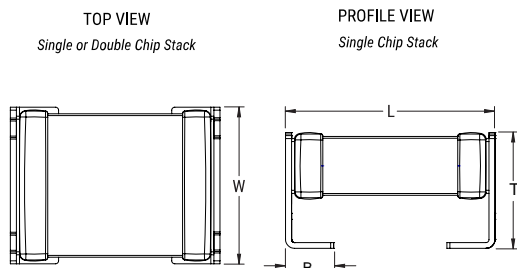

Dimensions	
L	6mm +/-0.5mm
W	5mm +/-0.5mm
T	3.5mm +/-0.30mm
B	1.6mm +/-0.3mm

Packaging Specifications	
Packaging:	T&R, 180mm, Plastic Tape
Packaging Quantity:	300

General Information	
Supplier:	KEMET
Series:	KPS SMD Auto X7R
Style:	Stacked Chip
Description:	SMD, MLCC, Stacked, Single Chip, Class II, Automotive Grade
Features:	Automotive Grade
RoHS:	Yes
Termination:	Tin
Qualifications:	AEC-Q200
AEC-Q200:	Yes
Miscellaneous:	Note: Referee time for X7R dielectric for this part number is 1000 hours
Chip Size:	2220-1
Shelf Life:	78 Weeks
MSL:	1

Specifications	
Capacitance:	2.2 uF
Capacitance Tolerance:	10%
Voltage DC:	50 VDC
Dielectric Withstanding Voltage:	125 V
Temperature Range:	-55/+125C
Temperature Coefficient:	X7R
Dissipation Factor:	2.50% 1kHz 25C
Aging Rate:	3% Loss/Decade Hour
Insulation Resistance:	455 MOhms