


**KEMET Part Number: 125MS26ACMA1STD**  
(A902GP125V260A)

MS/A902, Aluminum Electrolytic, Motor Start, 125 uF, -0/+25%, 260 VAC, -20/+60C

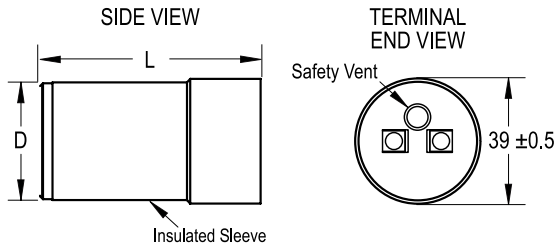

**Dimensions**

<b>D</b>	38mm +/-0.5mm
<b>L</b>	116mm MAX

**Packaging Specifications**

<b>Packaging:</b>	Bulk, Bag
-------------------	-----------

**General Information**

<b>Supplier:</b>	KEMET
<b>Series:</b>	MS/A902
<b>Dielectric:</b>	Aluminum Electrolytic
<b>Description:</b>	Motor Start Aluminum Electrolytic
<b>RoHS:</b>	Yes
<b>Lead:</b>	Quick Connect
<b>Shelf Life:</b>	156 Weeks

**Specifications**

<b>Capacitance:</b>	125 uF
<b>Capacitance Tolerance:</b>	-0/+25%
<b>Voltage AC:</b>	260 VAC
<b>Temperature Range:</b>	-20/+60C
<b>Rated Temperature:</b>	60C
<b>Life:</b>	500 Hrs