


C44A, Film, Metallized Polypropylene, Power, 10 uF, 5%, 330 VAC, 600 VDC

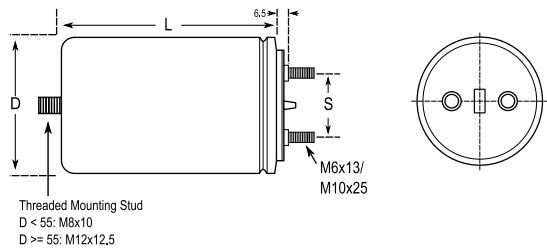

Dimensions

D	45mm +/-0.5mm
L	80mm +/-2mm
S	22.3mm +/-0.5mm

Packaging Specifications

Mounting:	Bolt - M8x10
Packaging:	Bulk, Bag
Packaging Quantity:	60

General Information

Supplier:	KEMET
Series:	C44A
Dielectric:	Metallized Polypropylene
Style:	Can
RoHS:	Yes
Lead:	Threaded Studs M6
Miscellaneous:	Thermal Resistance = 7.8 C/W

Specifications

Capacitance:	10 uF
Capacitance Tolerance:	5%
Voltage AC:	330 VAC
Voltage DC:	600 VDC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Max dV/dt:	40 V/us
Resistance:	5 mOhms (TYP)
Ripple Current:	16 Amps, 400 Amps (Peak)