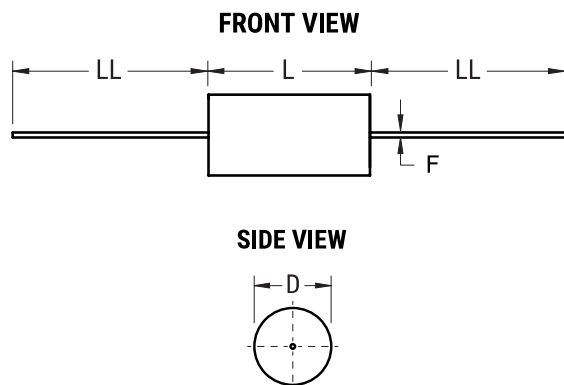


C4G, Film, Metallized Polypropylene, Power, 2.2 uF, 5%, 250 VAC, 400 VDC, 70C

**Dimensions**

<b>D</b>	17.5mm MAX
<b>L</b>	33mm MAX
<b>LL</b>	40mm +/-5mm

**Packaging Specifications**

<b>Packaging:</b>	Bulk, Bag
<b>Packaging Quantity:</b>	150

**General Information**

<b>Supplier:</b>	KEMET
<b>Series:</b>	C4G
<b>Dielectric:</b>	Metallized Polypropylene
<b>Style:</b>	Axial
<b>Features:</b>	Switching
<b>RoHS:</b>	Yes
<b>Lead:</b>	Wire Leads
<b>Miscellaneous:</b>	Polyester Tape & Resin Protection

**Specifications**

<b>Capacitance:</b>	2.2 uF
<b>Capacitance Tolerance:</b>	5%
<b>Voltage AC:</b>	250 VAC
<b>Voltage DC:</b>	400 VDC
<b>Temperature Range:</b>	-40/+85C
<b>Rated Temperature:</b>	70C
<b>Dissipation Factor:</b>	0.05%
<b>Max dV/dt:</b>	45 V/us
<b>Resistance:</b>	4.4 mOhms (100KHz)
<b>Ripple Current:</b>	9 Amps (100kHz 70C), 99 Amps (Peak)