


C27, Film, Film/Foil Polypropylene, Motor Run, 4 uF, 5%, 470 VAC

Double Faston

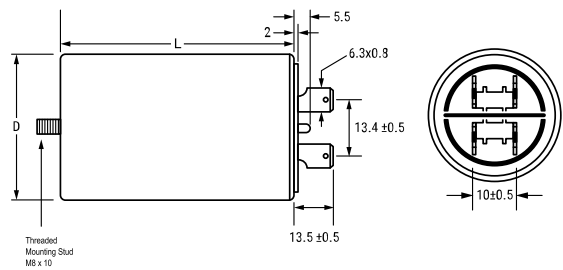

**Dimensions**

D	30mm +1mm
L	56.5mm +/-2mm

**Packaging Specifications**

Mounting:	Bolt-M8x15
Packaging:	Bulk, Bag

**General Information**

Supplier:	KEMET
Series:	C27
Dielectric:	Film/Foil Polypropylene
Style:	Can
Description:	Plastic Case and Cover, Ultra Sonically Welded Seal
Features:	Ultra Sonically Welded Seal, Safety Class P0, UL_94 V0 Disk
RoHS:	Yes
Lead:	Fast On (2+2)
Qualifications:	UL, VDE, UL (Construction Only), UL_94 V0 Disk

**Specifications**

Capacitance:	4 uF
Capacitance Tolerance:	5%
Voltage AC:	470 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85C
Max dV/dt:	20 V/us