
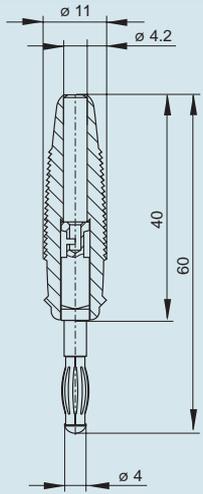


Plugs

4 mm system

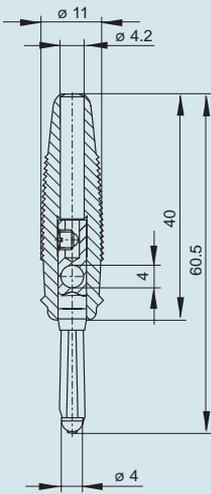

4 mm system

Product description	Laminated, shatter-proof plug with caged spring and tapering sleeve providing protection against kinking. Soldered connections up to 1.5mm ² , cable diameters up to 4.2 mm. Nickel-plated brass contact, nickel-plated copper beryllium contact spring.	Multiple-spring wire plug, shatter-proof, flexible insulated sleeve with transverse hole. The tapering sleeve end also serves as kinking protection for the lead. Screw connection up to maximum cable cross-section of 1.5 mm ² . Nickel-plated brass contact material.
	LAS 30 schwarz/black	BUELA 20 K rot/red
	972 518-100	930 726-101
	4 mm safety system	4 mm System
	black	red
		
	red color, order no. 972 518-101	black color, order no. 930 726-100; blue color, order no. 930 726-102; yellow color, order no. 930 726-103; green color, order no. 930 726-104
Drawing		
Technical data	4 mm with laminated spring pin (spring-loaded) solder DC 60 V 32 A 3 mOhm	4 mm pin (spring-loaded) screw DC 60 V 16 A 3 mOhm
Material	copper beryllium nickel-plated PVC-P	brass nickel-plated PVC-P
Environmental conditions	-25 °C to +70 °C	-25 °C to +70 °C
Inflammability class	94 V-2	94 V-2