


**KEMET Part Number: SC-02-10J**  
(UALSC0210J0000)

KEMET, SC-J, AC Line Filters, Common Mode, 1000 uH

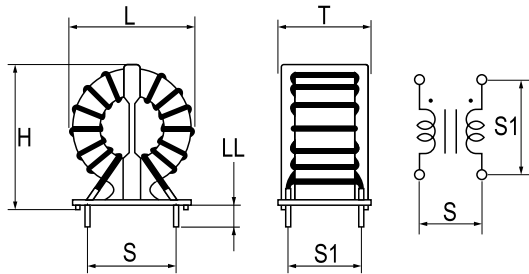

**Dimensions**

|           |            |
|-----------|------------|
| <b>L</b>  | 25mm MAX   |
| <b>T</b>  | 20mm MAX   |
| <b>H</b>  | 27mm MAX   |
| <b>LL</b> | 5mm +/-2mm |
| <b>S</b>  | 15mm NOM   |

**Packaging Specifications**

|                            |      |
|----------------------------|------|
| <b>Packaging:</b>          | Tray |
| <b>Packaging Quantity:</b> | 400  |
| <b>Weight:</b>             | 15 g |

**General Information**

|                       |   |
|-----------------------|---|
| <b>Series:</b>        | SC-J  |
| <b>Style:</b>         | Through-Hole                                |
| <b>RoHS:</b>          | Yes   |
| <b>Notes:</b>         | Lead Spacing (S/S1) Are For Reference Only. |
| <b>Miscellaneous:</b> | Temperature Rise Maximum: 40 K              |

**Specifications**

|                           |           |
|---------------------------|-----------|
| <b>Voltage AC:</b>        | 250 VAC   |
| <b>Inductance:</b>        | 1 mH      |
| <b>Current:</b>           | 2 A       |
| <b>Temperature Range:</b> | -25/+120C |
| <b>DC Resistance:</b>     | 100 mOhms |