


KEMET Part Number: SHO-102
(SHO102)

KEMET, SHO, DC Line Filters, Common Mode, 600 nH

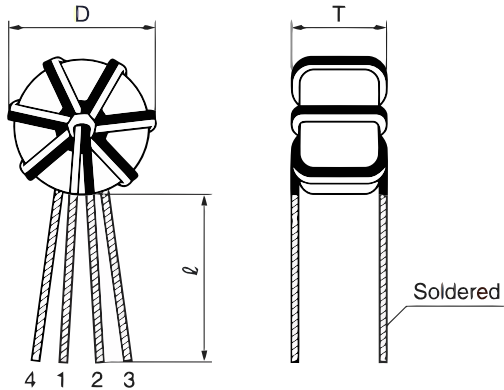

Dimensions

L	11mm MAX
T	7.5mm MAX
H	11mm MAX
LL	10mm +/-3mm

Packaging Specifications

Packaging:	Bulk, Box
Packaging Quantity:	6000
Weight:	1.05 g

General Information

Series:	SHO
Style:	Through-Hole
RoHS:	Yes

Specifications

Voltage DC:	50 VDC
Inductance:	0.6 uH
Temperature Range:	-25/+70C
DC Resistance:	10 mOhms