


KEMET Part Number: SU10VFC-R10045
(UALSU10VR10045)

KEMET, SU-10VFC-R, AC Line Filters, Common Mode, 4500 uH

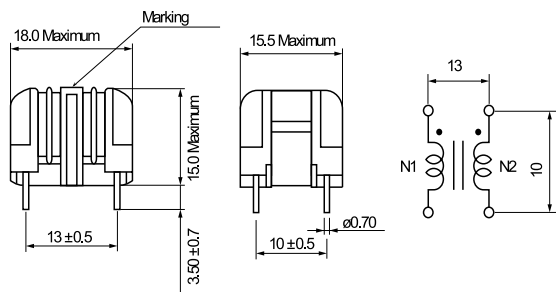

Dimensions

L	18mm MAX
T	15.5mm MAX
H	15mm MAX
LL	3.5mm +/-0.7mm
S	10mm +/-0.5mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	700
Weight:	6.4 g

General Information

Series:	SU-10VFC-R
Style:	Through-Hole
RoHS:	Yes
Miscellaneous:	Temperature Rise Maximum: 50 K

Specifications

Voltage AC:	250 VAC
Inductance:	4500 uH
Current:	1 A
Temperature Range:	-25/+120C
DC Resistance:	550 mOhms