


**KEMET Part Number: SS11VL-R11076**  
(UAL11VLR110760)

KEMET, SS11VL, AC Line Filters, Common Mode, 7600 uH

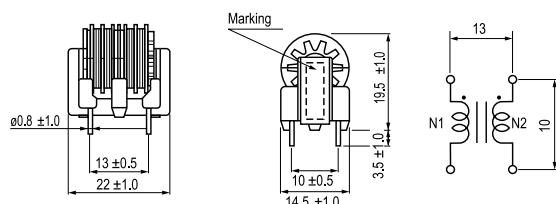

#### Dimensions

<b>L</b>	22mm +/-1mm
<b>T</b>	14.5mm +/-1mm
<b>H</b>	19.5mm +/-1mm
<b>LL</b>	3.5mm +/-1mm
<b>S</b>	10mm +/-0.5mm

#### Packaging Specifications

<b>Packaging:</b>	Tray
<b>Packaging Quantity:</b>	600
<b>Weight:</b>	10.7 g

#### General Information

<b>Series:</b>	SS11VL
<b>Style:</b>	Through-Hole
<b>RoHS:</b>	Yes
<b>Notes:</b>	Lead Spacing (S/S1) Are For Reference Only.
<b>Miscellaneous:</b>	Temperature Rise Maximum: 45 K

#### Specifications

<b>Voltage AC:</b>	250 VAC
<b>Inductance:</b>	7.6 mH
<b>Current:</b>	1.1 A
<b>Temperature Range:</b>	-25/+120C
<b>DC Resistance:</b>	400 mOhms