


KEMET Part Number: SS17HB-R03300 **Not for New Design**
(UAL17HBR033000)

KEMET, SS17HB, AC Line Filters, Common Mode, 0.03 H

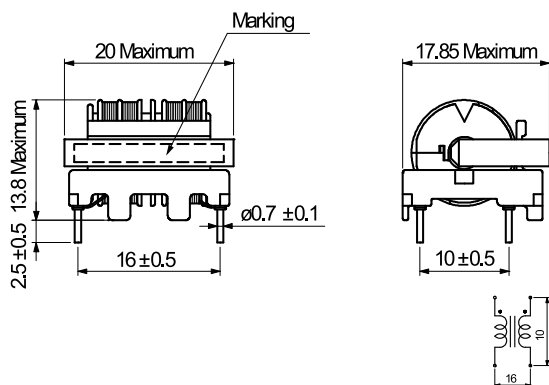

Dimensions

L	20mm MAX
T	17.85mm MAX
H	13.8mm MAX
LL	2.5mm +/-0.5mm
S	10mm +/-0.5mm

Packaging Specifications

Weight:	5.9 g
---------	-------

General Information

Series:	SS17HB
Style:	Through-Hole
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530 or equivalent

Specifications

Voltage AC:	250 VAC
Inductance:	30 mH
Current:	300 mA
Temperature Range:	-25/+120C
DC Resistance:	2.6 Ohms