


KEMET Part Number: SS17HB-R13020 **Not for New Design**
(UAL17HBR130200)

KEMET, SS17HB, AC Line Filters, Common Mode, 2000 uH

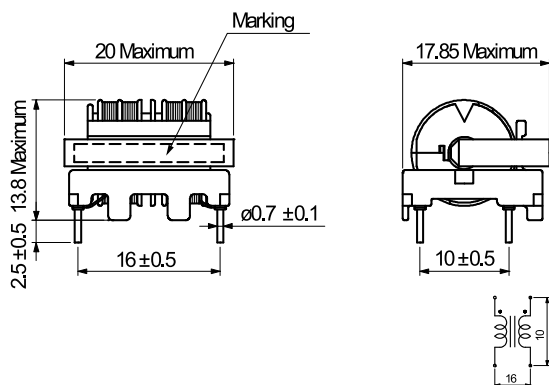

Dimensions

| | |
|----|----------------|
| L | 20mm MAX |
| T | 17.85mm MAX |
| H | 13.8mm MAX |
| LL | 2.5mm +/-0.5mm |
| S | 10mm +/-0.5mm |

Packaging Specifications

| | |
|---------|-------|
| Weight: | 6.2 g |
|---------|-------|

General Information

| | |
|----------------|---|
| Series: | SS17HB |
| Style: | Through-Hole |
| RoHS: | Yes |
| Miscellaneous: | Inductance Measurement Condition: 1kHz 1V KC530 or equivalent |

Specifications

| | |
|--------------------|-----------|
| Voltage AC: | 250 VAC |
| Inductance: | 2 mH |
| Current: | 1.3 A |
| Temperature Range: | -25/+120C |
| DC Resistance: | 180 mOhms |