
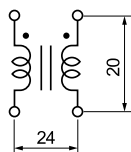


**KEMET Part Number: SS28H-R10450-CH** **Not for New Design**  
(UAL28HR10450CH)

KEMET, SS28V/H-CH, AC Line Filters, Common Mode, 0.045 H

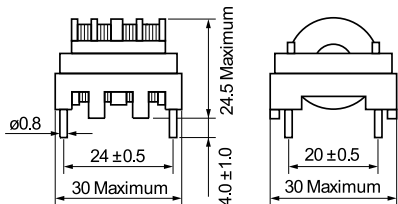

#### Dimensions

L	30mm MAX
T	30mm MAX
H	24.5mm MAX
LL	4mm +/-1mm
S	20mm +/-0.5mm

#### Packaging Specifications

Weight:	31 g
---------	------

#### General Information

Series:	SS28V/H-CH
Style:	Through-Hole
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530

#### Specifications

Voltage AC:	250 VAC
Inductance:	45 mH
Current:	1 A
Temperature Range:	-25/+120C
DC Resistance:	650 mOhms