


## KEMET, EFS, Flex Suppressors, Noise Suppression

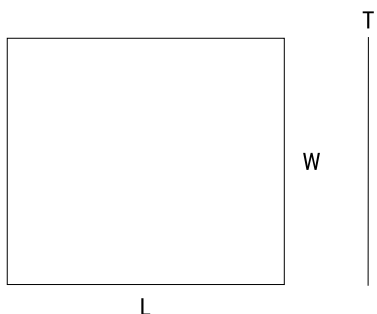

General Information	
Series:	EFS
Style:	Sheet
Description:	Flex Suppressor Super High Frequency Type
Features:	Super High Frequency
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
Sheet Size	240x240mm
L	240mm NOM
W	240mm NOM
T	0.3mm NOM

Specifications	
Temperature Range:	-40/+105C
Magnetic Permeability:	10 u At 3MHz
Effective Frequency:	40 GHz Max
Resistance:	100 MOhms MIN
Specific Gravity:	4.5 Atm TYP

Packaging Specifications	
Weight:	75.1 g