


KEMET, MPLCV, Power, 33 uH, 20%

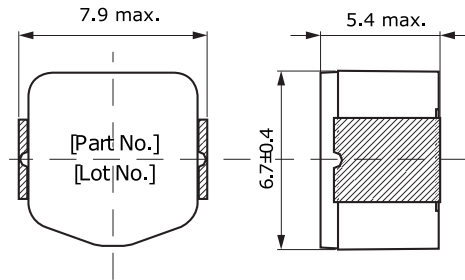

General Information	
Series:	MPLCV
Style:	SMD
Description:	Surface Mount Inductor
Features:	Power Inductors, Automotive
RoHS:	Yes
Qualifications:	AEC-Q200
AEC-Q200:	Yes
Core:	Composite
Miscellaneous:	40 (K) Temperature Rise Max.

Dimensions	
Chip Size	3126
L	7.9mm MAX
W	6.7mm +/-0.4mm
T	5.4mm MAX

Specifications	
Inductance:	33 uH (0.1 MHz)
Inductance Tolerance:	20%
Temperature Range:	-55/+155C
Shielded:	Yes
Current:	4 A (Isat, 30% Drop In Inductance), 2.6 A (Irms, 40C Rise By Self Heating)
DC Resistance:	140 mOhms

Packaging Specifications	
Packaging:	T&R, 380mm
Packaging Quantity:	1000