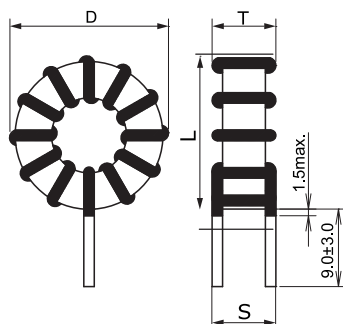


KEMET, SHBC, AC Line Filters, Normal Mode, 45 uH, 20%

**Dimensions**

D	30mm MAX
L	30mm MAX
T	30mm MAX
LL	9mm +/-3mm
S	11mm NOM

**Packaging Specifications**

Packaging:	Tray
Packaging Quantity:	150
Weight:	23 g

**General Information**

Series:	SHBC
Style:	Through-Hole
Features:	Low Core Loss, High Frequency Drive
RoHS:	Yes
Miscellaneous:	25 (K) Temperature Rise Max.

**Specifications**

Inductance:	45 uH
Inductance Tolerance:	20%
Current:	6 A
Temperature Range:	-40/+125C
DC Resistance:	18.3 mOhms