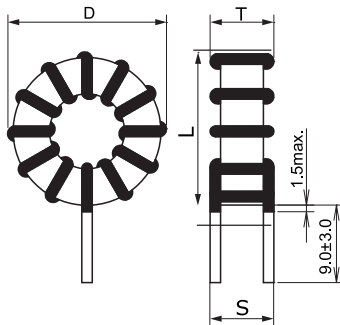


KEMET, SHBC, AC Line Filters, Normal Mode, 81 uH, 20%

**Dimensions**

D	30mm MAX
L	30mm MAX
T	30mm MAX
LL	9mm +/-3mm
S	11mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	150
Weight:	26 g

General Information

Series:	SHBC
Style:	Through-Hole
Features:	Low Core Loss, High Frequency Drive
RoHS:	Yes
Miscellaneous:	30 (K) Temperature Rise Max.

Specifications

Inductance:	81 uH
Inductance Tolerance:	20%
Current:	6 A
Temperature Range:	-40/+125C
DC Resistance:	24.7 mOhms