


**KEMET Part Number: FM0H224ZF**  
(USCFM00H224Z00)

FM, Supercapacitors, Radial Molded, Commercial Grade, 0.22 F, -20/+80%, 5.5 VDC, Wire Leads, Lead Spacing = 5mm

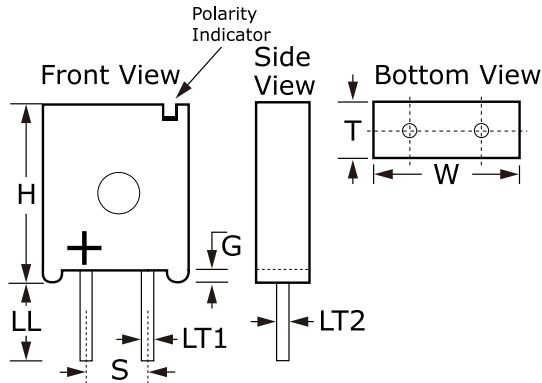

#### Dimensions

Dimension	Value
W	10.5mm +/-0.5mm
H	11.5mm +/-0.5mm
T	6.5mm +/-0.5mm
S	5mm +/-0.5mm
LL	5mm +/-1mm
G	0.4mm +/-0.1mm
LT1	0.5mm +/-0.1mm
LT2	0.4mm +/-0.1mm

#### Packaging Specifications

Lead:	Wire Leads
Packaging:	Bulk, Bag

#### General Information

Supplier:	KEMET
Series:	FM
Description:	Radial Molded Double Layer Capacitor
RoHS:	Yes
Miscellaneous:	DischargeValue = 0.22 F

#### Specifications

Capacitance:	0.22 F
Capacitance Tolerance:	-20/+80%
Voltage DC:	5.5 VDC
Temperature Range:	-25/+70C
Rated Temperature:	70C
Resistance:	100000 mOhms (1kHz)