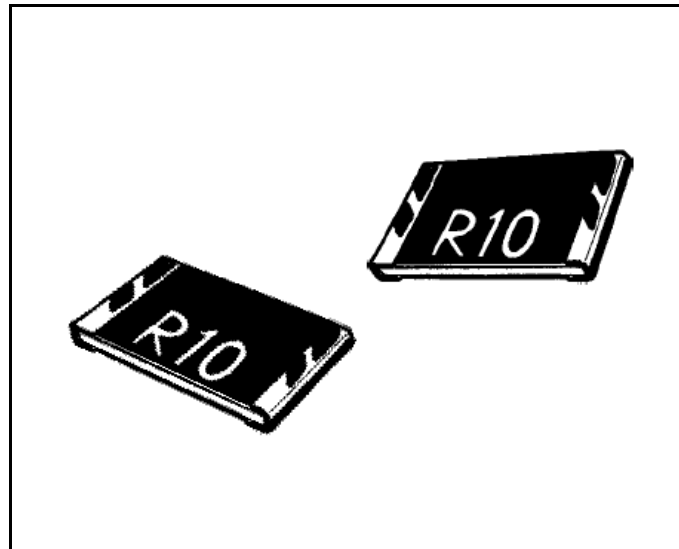

SMD Low Ohmic - Current Sense Resistors

**TYPE TL SERIES**

Tyco are pleased to offer this unique High Power, metal chip resistor for current sensing positions. It has a special metal resistive element and suitable barrier layers underneath the solder to prolong terminal life. Following the developments by semiconductor manufacturers in the production of a range of IC's for battery charge management and low voltage power supplies, the TL Series satisfies the demand for a low ohmic shunt resistor to act as a current sensor. It has particular applications in the automotive industry for sensing in EMU's.

KEY FEATURES

- Low Cost for Volume Applications
- Up to 1 Watt at 70°C
- Supplied on Tape
- Ideal for Current Detection
- Wide Value Range R005 to 1R0 Possible
- Fully Automated Manufacture
- 12:06, 20:10 and 25:12 Packages Available
- Available in Distribution

STOCKISTS:

This product is available from RS and Farnell.

TYPE TL SERIES

1st April 2003
ISSUE 9

ELECTRICAL


Resistance Value Range:	R01 - 1R0 (R005 is available in a TL3A Package only)
Stock Values:	R01, R015, R018, R022, R033, R047
Resistance Tolerance:	±1%
Power Rating:	Up to 1 watt at 70°C derating to zero at 170°C
Operating Temperature:	-65°C to +170°C
Inductance:	< 5 Nanohenries
T.C.R.	±75ppm/°C

MECHANICAL

Body Construction:	Fully Welded Element
Terminations:	60/40 Tinned Copper
Coating:	Epoxy

POWER RATING CURVE


For resistors operated in ambient temperatures above 70°C, power rating must be derated in accordance with the curve.

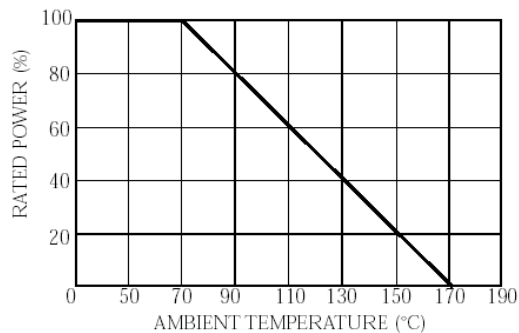

Type	Power Rating
TL2B	0.25 Watts
TL2H*	0.5 Watts
TL3A	1.0 Watts

DIMENSIONS

Type	A	B	C	D
TL2B	3.2	1.6	0.6	0.5
TL2H*	5.1	2.5	0.6	0.5
TL3A	6.4	3.2	0.6	0.8

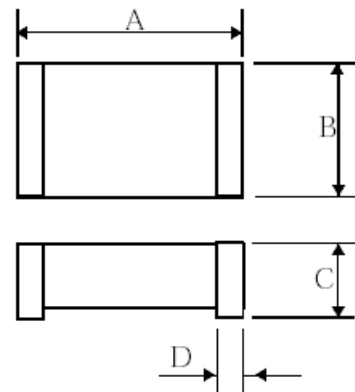

Reel Quantities:

12:06 - 4000 on 7" Reel
25:12 - 2000 on 7" Reel

All Dimensions are Nominal and in mm. Do Not Scale.

HOW TO ORDER

TL	3A	R015	F	TE	
COMMON PART	POWER RATING	RESISTANCE VALUE	TOLERANCE	PACKAGING	
TL - Standard Part	2B - 12:06 2H - 20:10 3A - 25:12	0.005 ohm (5 milli ohm) 0.015 ohm (15 milli ohms) 0.047 ohm (47 milli ohms)	R005 R015 R047	F - ± 1%	TE - 4000 per Reel TDG - 2000 per Reel

N.B. * - 20:10 available by special request. Minimum Orders of 10000 pcs to apply

This publication is issued to provide outline information only and (unless specifically agreed to the contrary by the Company in writing) is not to form part of any order or be regarded as a representation relating to the products or service concerned. We reserve the right to alter without notice the specification, design, price or conditions of supply of any product or service. Whilst Tyco Electronics Components products are of the very highest quality and reliability, all electronic components can occasionally be subject to failure. Where failure of a Tyco Electronics Components product could result in life threatening consequences, then the circuit and application must be discussed with the Company. Such areas might include ECG, respiratory and other medical and nuclear applications and any non fail-safe applications circuit.