

PS12_SCAS_0000_SM09E_XX.X_S0

Description

12 pigtail set, SC-HQ BTW, APC, fiber 0.9mm_XX.X_fiber colour EN / IEC, SM G.652.D



Features	Features
- Push-pull connector	
- One-piece design for easy and quick termination	
- High mechanical and thermal resistance according to Telcordia GR-326-CORE	

Technical Data

General Data

Description	Values
General Typ	SC pigtail
Operation temperature	-40 up to 85°C
RoHS compliant 2001/65/EU	Yes
REACH compliant	No

Connector left


Description	Values
Connector typ	SC pigtail
Polish	APC
Color Housing	Black
Color Boot	Green
Design connector acc. To	IEC 61754-4, TIA 604-3
Performance class H+S	0
Insertion loss 97% dB / mean dB	0.25 / 0.12
Return Loss	>65dB
Durability	1000

Cable

Description	Values
Cable typ	Semi-tight Tube
Fiber count	1
Fiber	1 x 0.9 mm
Fiber typ	E9/125-SM standard G.652.D

PS12_SCAS_0000_SM09E_XX.X_S0

Technical Drawing

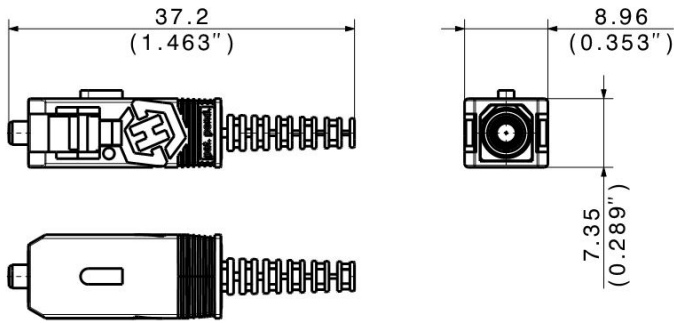

Ordering information

Meter (m)	Item number	Description
-----------	-------------	-------------