


## Fiberframe Lite

### Description

Fiberframe Lite, 24 x SC adaptor blue  
 FL1-BSCUS-2400-SM-000-0O00

#### Features

- Standard 19" 1U size
- Robust steel construction
- Telescopic drawer with tilt of 15°
- Multifunctional back plate
- Up to 24 fibers per 1U
- ACS splice cassette technology accepting up to 24 fibers per cassette
- Optional zero space cable management bar

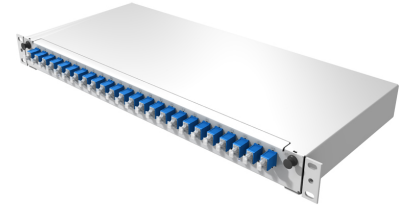

### Technical data

#### Mechanical data


Characteristics	Values
Product family	Fiberframe
Suitable for	Patching
Dimension (Width x Length x Height) (mm)	448 x 200 x 44
Dimension (Width x Length x Height) (inch)	17.6 x 7.9 x 1.7
Weight (kg)	2.3
Weight (lbs)	5.1
Material module	powder coated steel
Colour module	light grey (RAL 7035)
Mounting type	Front mounting
Drawer Tilt (°)	15
Number of Adaptor front (pcs)	24
Adaptor type front	SC
Adaptor colour front	blue

#### Environmental data

Characteristics	Values
Resistance to impact	IK03
Ingress protection degree	IP20
Free of halogen	Yes
RoHS compliant	Yes
REACH compliant	Yes

## Fiberframe Lite

### Technical drawing

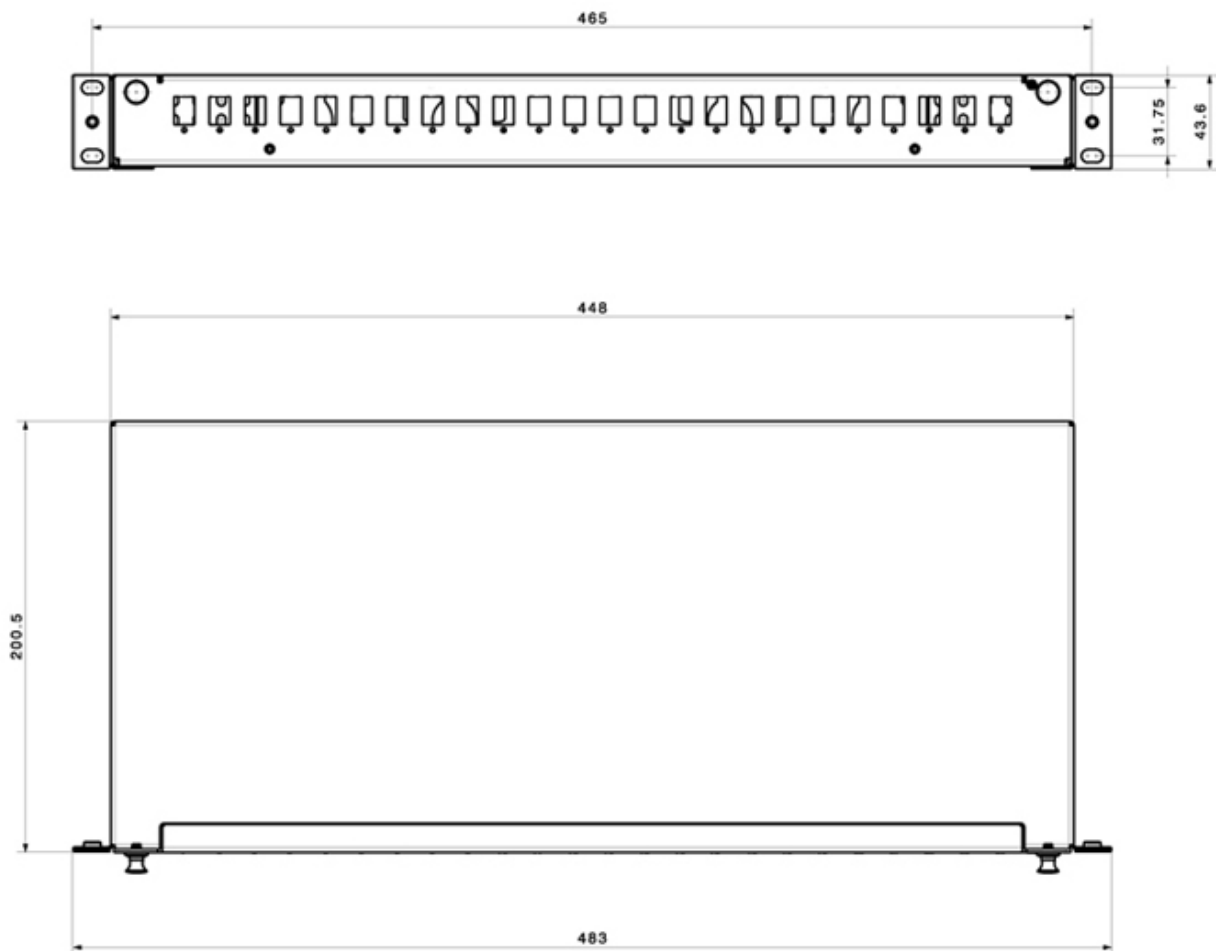

### Ordering information

Description	Item number
Fiberframe Lite, 24 x SC adaptor blue	85063229

### Related Documents

Installation manual	DOC-0000711379
---------------------	----------------