


TITLE: 1 W 1GHZ BNC/m COAXIAL TERMINATION

LTR. E

DRAWING

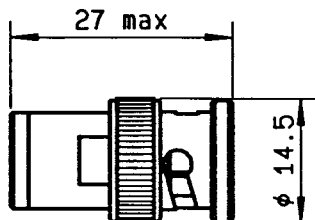

PACKAGING		
Standard	Unit	Other
100	"W" option	Contact us

Without marking

General tolerances: +/- 0.5 mm

ELECTRICAL CHARACTERISTICS

FREQUENCY RANGE	: DC - 1GHz
IMPEDANCE	: 50 Ohms
DC RESISTANCE	: 50 Ohms ± 1%
AVERAGE POWER HANDLING	: 1 W at 25°C
PEAK POWER HANDLING	: 500 W (1 μs, 1%.) at 25°C


MECHANICAL CHARACTERISTICS

CONNECTOR	: BNC male per MIL C 39012
MAXIMUM WEIGHT	: 15 grams

ENVIRONMENTAL CHARACTERISTICS

OPERATING TEMPERATURE RANGE (°C)	: -55 , +125
STORAGE TEMPERATURE RANGE (°C)	: -55 , +125

Power derating
Versus temperature

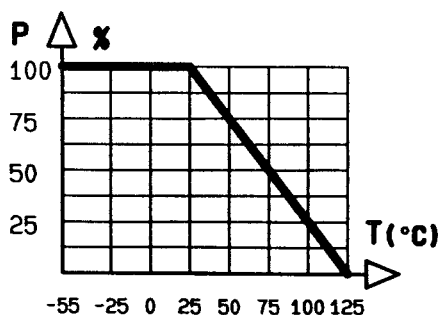

Tentative data subject to change without notice

PEN CAT	QUALITY Dpt App.				
			Add packaging	DM02-07-015 VIGNARD	01.10.02 JARRAND
			E	new format	20.10.92 VE
PAGE 1/1	DATE 17.03.89	NAME CS	D	New design	06.08.91 KL
	LTR	REVISIONS		DATE	APP.