




**2205**

50mm/ 2" Swivel Castor. 24mm/ 15/16" Wide Wheel with Single Row Ball Bearing Swivel Raceway. NSF Certified.  
 Add SB for Side Brake(SR,HR,PU Only).  
 Rigid Part#: 2202, Add Wheel Type to End of Part#.  
 Thread width: 15/16. Overall height: 2-7/16. Swivel Radius: 1 3/4  
 Top Plate: Overall Size : 1-7/8 x 2-9/16. Bolt hole Spacing : 15/16 x 2-1/8  
 Attaching Bolt Size : 1/4

**Special Order outside USA & China**

Material: Steel/Zinc

Part Number	Wheel	Bearing	Load Capacity
<b>2205LP</b>	Plastic	Plain	56.7Kg/125lb
<b>2205PU</b>	Polyurethane	Plain	56.7Kg/125lb

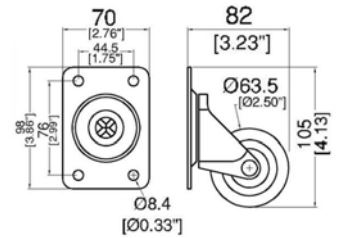


**2255**

63mm/ 2 1/2" Swivel Castor, with 28mm/ 1 1/8" Wide Wheel.  
 NSF Certified.  
 Single Row Ball Bearing Swivel Raceway.  
 Add SB for Side Brake(SR,HR,PU Only).  
 Rigid Part#: 2252, Add Wheel Type to End of Part#.

**Special Order outside USA & China**

Material: Steel/Zinc

Part Number	Wheel	Bearing	Load Capacity
<b>2255SR</b>	Soft Rubber	Nylon	45.4Kg/100lb
<b>2255HR</b>	Hard Rubber	Nylon	90.7Kg/200lb
<b>2255LP</b>	Plastic	Plain	79.4Kg/175lb

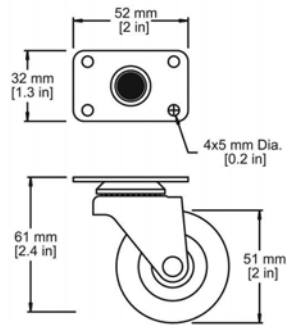

**1204Z394**

50mm/2" Light Duty Swivel Castor, with Hard Rubber Black Wheel.  
 Single Row Ball Bearing Swivel Raceway.  
 Load Capacity 36.3Kg/80lb.

**Special Order outside USA & China**

Material: Steel/Zinc

Part Number	Description
<b>1204Z394</b>	Swivel



**5291-5292-5293**

50mm / 2" Push in Castor with Soft Rubber Wheel  
 Load Capacity 45.4Kg/100lb (Sold separately).  
 Can be used with castor plates 0115 and 0117

**Special Order outside USA & China**

Material: Steel/Zinc

Part Number	Description
<b>5291</b>	Swivel
<b>5292</b>	Swivel with Side Brake
<b>5293</b>	Rigid