

WIFI SMART BULB LED GU10 DIMMABLE



SKU Code: SHA5216
EAN Code: 7103356628409

Wifi Smart Bulb LED GU10 Dimmable, Warm White to Cool White (2000K-6500K),

Works with Alexa and Google Home, 5W Equal to 50W Spot Light, Controlled by ENERJSMART app



Download Our App




ENERJSMART

Technical Details

Wattage	5W
Lumens	420Lm
Color Temperature	2000k-6500k
Voltage	170-240V
Dimmable	Yes
Average Life	20,000 hrs
Size	50x50x56mm
Item Weight	125g

Features

- Alexa turn the Light to warm white: No hub required, works great with Echo, Google Home and IFTTT, so that you can easily control your lights with just voice command.
- Tunable White: You can change the color temperature of this GU10 Spotlight from 2000k to 6500k.
- Remotely control your lights: Use your ENER-J WiFi GU10 as a security light. When you are going for a holiday, you can turn it on/off by only one click via your phone (ENERJ Smart APP), protecting the safety of your household.
- Timer function: With a timer function, it can be set up to switch on with sunshine warm light in the morning when your normal alarm goes off.
- Light your home smarter: One can be widely use ENER-J's WiFi GU10 in kitchen, living room, bedroom, study or hallways, in your table and floor lamps, pendant fixtures or ceiling fixtures, thereby converting your home into a smart one.

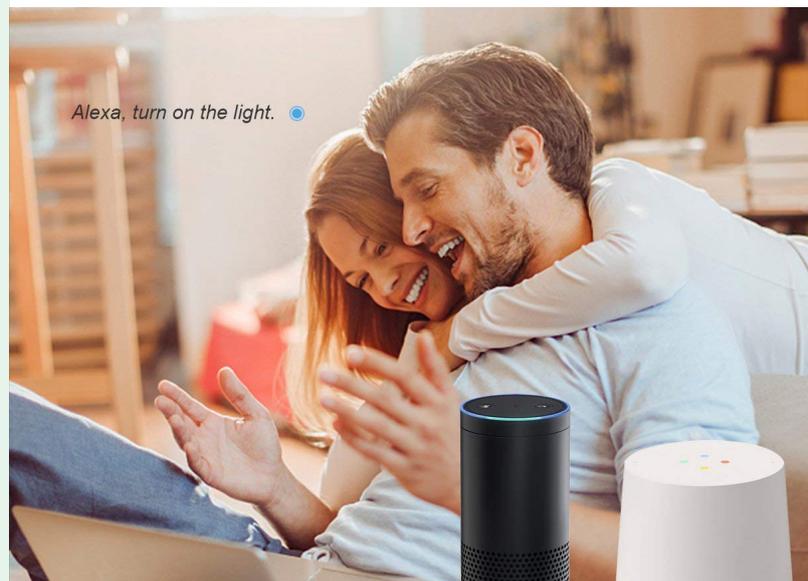

Works with Amazon Alexa, Google Home and IFTTT. Control your light via your voice!

Voice Control

